



# 1m Neutral White LED Strip Mounted in Right Angle Aluminium Profile

Order code: **76-0054**


MPN: SAP-YD1203-HD-NW



## Features:

- 18x18mm lightweight aluminium profile
- High performance LED emitters
- Safe, low voltage operation 12V DC
- Long life, low maintenance
- Diffused lens
- Choice of colour temperatures

The SAP-YD1203 series right angle (corner) linear LED fitting is constructed from anodised aluminium and is designed for local area illumination for a wide range of applications.

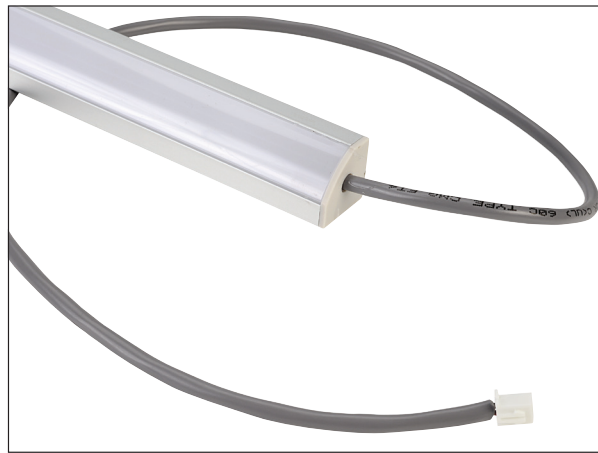

Order code	Colour	Suffix	CCT °K	Voltage Vdc	Angle
<b>76-0054</b>	Natural White	NW	4000~4500K	12V	120°

Dimensions	Lumen output Typ.	Power		LED Qty.
		Typical	Max.	
1000x18x18mm	820	7.5W	9.6W	117

- Terminated with 500mm input lead and XHP-2 connector
- Supplied with mounting clips for ease of installation
- Use in conjunction with external constant voltage driver

## Notes:

These units are designed for low voltage dc operation and must not be connected directly to AC mains. Luminous Flux values quoted are typical. Please contact our office for the latest luminous intensity yields. Specifications may be subject to change without notice.

## Dimensions (mm):

