

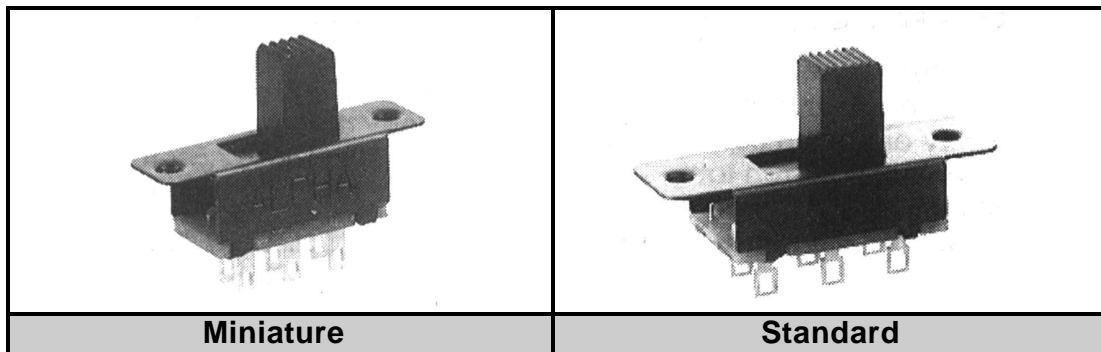
## Slide switches

Order code	Manufacturer code	Description
76-0100	n/a	DPDT MINIATURE SLIDE SWITCH (RC)
76-0105	n/a	DPDT STANDARD SLIDE SWITCH (RC)
76-0110	n/a	DPDT C/O STANDARD SLIDE SWITCH (RC)

Slide switches	Page 1 of 2
The enclosed information is believed to be correct, Information may change without notice due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 20/02/2007

# Slide Switches

## Photographs



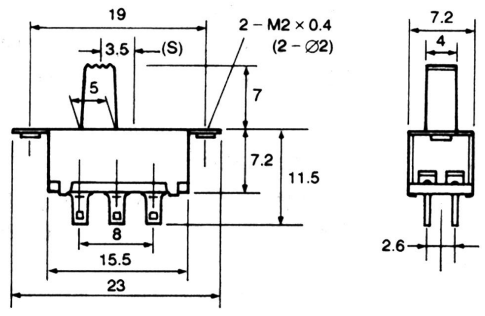
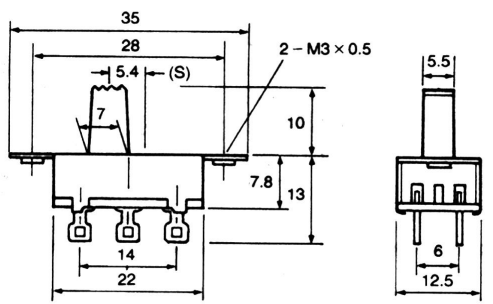
## Description

A range of miniature and standard slide switches suitable for a wide range of electronic applications & equipment. Break before make DPDT contacts and terminations are made via solder terminals.

## Technical Specifications

Maximum Voltage	:	$< 80\text{Vac}$ (advised)
Maximum Current Rating	:	300mA
Termination type	:	Solder
Soldering Temperature	:	330°C for 3 Seconds.

## Technical Drawings

<b>Mini Slide</b>	
<b>Standard Slide</b>	
<b>Centre Off Slide</b>	