


Features:

- Positive detent

Applications/Markets

- Computer servers/peripherals
- Consumer electronics
- Instrumentation
- Test & measurement

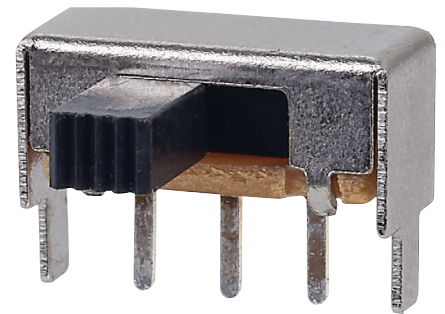

Specifications

Contact resistance	Less than 20 milliohms
Insulation resistance	500 V DC – 100 milliohms
Dielectric strength	500 V AC for 1 minute between any terminal and frame
Operating temperature	-20°C to +70°C (-4°F to +158°F)

Materials

Contact	Silver plated copper alloy
---------	----------------------------

