


Part Number: S1016CW (Alternate Part No: AG3011-77C)
Encapsulated Tilt Switch
Product Data Sheet

PICTURE



✓ RoHS Compliant

OPERATION

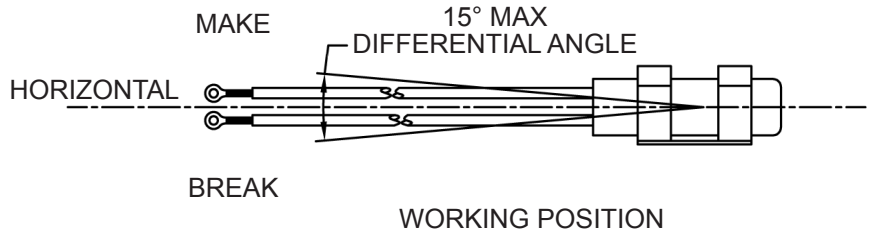


FEATURES

- Resistant to Ambient Environmental Conditions
- Case Material : Plastic Housing
- Construction : Thermo Resist Epoxy Encapsulated
- Wires : #18 AWG Stranded Copper Wire, Black Neoprene Insulated

DIMENSIONS

Drawings not to scale.
 All dimensions in inches (mm) nominal.

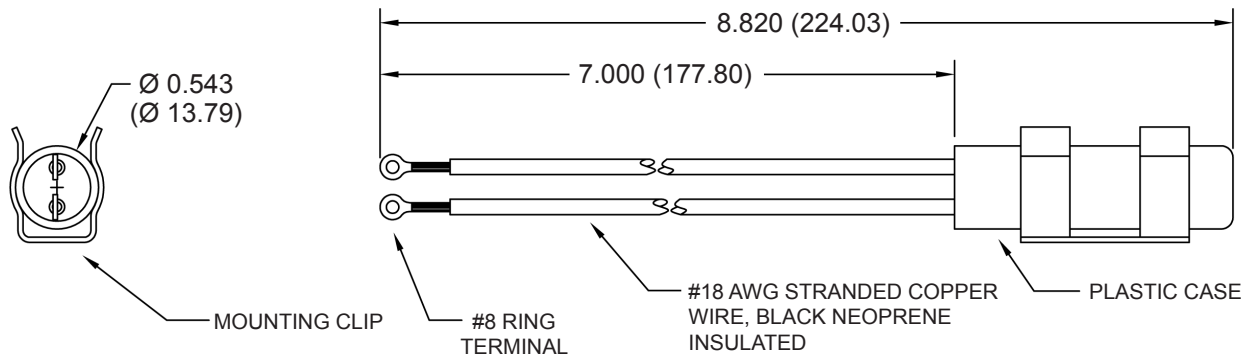

SPECIFICATION

Contact Capacity	1 A MAX at 6 - 24 VDC
Contact Resistance	3 Ohms MAX
Make Angle	10° MAX below horizontal
Break Angle	10° MAX above horizontal
Differential Angle	15° MAX

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

Phone: (1) 973 777 6900 **www.comus-intl.com** **Fax: (1) 973 777 8405**