

Push switches

Order code	Manufacturer code	Description
78-1706	MP0033	VANDAL RESIST.SWITCH SPNO


Push switches	Page 1 of 2
The enclosed information is believed to be correct, Information may change 'without notice' due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 04/07/2003

Vandal Resistant Switch SPNO

Bulgin – MP0033

Specifications

Bulgin List No:	MP0033
Terminations:	Screw terminals
Switching:	S.P. Push to make Slow momentary action
Current Rating:	1A max.
Voltage Rating:	50V AC
Contact Resistance:	<15mΩ
Insulation Resistance:	>10 ⁴ MΩ
Dielectric Strength:	>2.5kV AC
Operating Temp. Range:	-20°C to +85°C
Sealing:	Internally sealed against ingress of water and dust
Materials:	
Mouldings:	Glass Filled Nylon
Switch Body:	Brass, Chrome Plated
Button:	Stainless Steel
Tags/Terminals:	Brass, Silver plated
Contacts:	Copper, Silver Plated
Max. Panel Thickness:	15.0mm
Mounting Hole:	19mm ±0.10mm

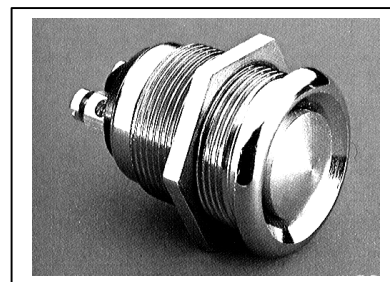

Dimensions

