 
 
 
 



Item no.: 2998049

Data Sheet

Battery switch, 12-50 V DC, 300 A, ON-OFF

Voltage		50VDC Max.		Mounting Hole		Actions Diagram		Circuit Diagram	
Continuous Rating		300 Amps		A		B			
Intermittent Rating		500 Amps							
Cranking Rating		1000 Amps 30 sec.							
Contact Resistance		50m ohm Max.							
Switch Operation		ON / OFF(SEPARATE)							

The twist switch knob can be removed

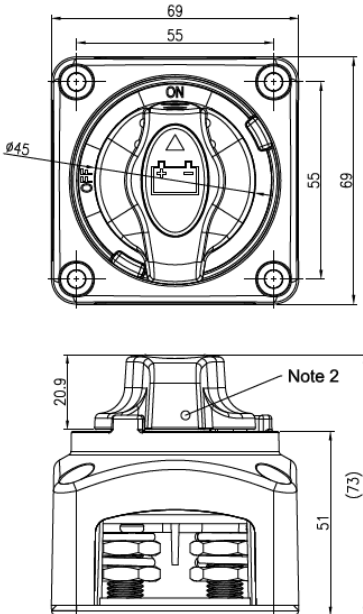

Top view dimensions: 69, 55, 55, 69, 55,