


DIL switches

Order code	Manufacturer code	Description
80-0170	n/a	HORIZONTAL HEX BCD SWITCH
80-0175	n/a	HORIZONTAL DECIMAL BCD SWITCH

DIL switches	Page 1 of 2
The enclosed information is believed to be correct, Information may change 'without notice' due to product improvement. Users should ensure that the product is suitable for their use. E. & O. E.	Revision A 04/07/2003

DIP rotary switches

DIMENSIONS: (mm)

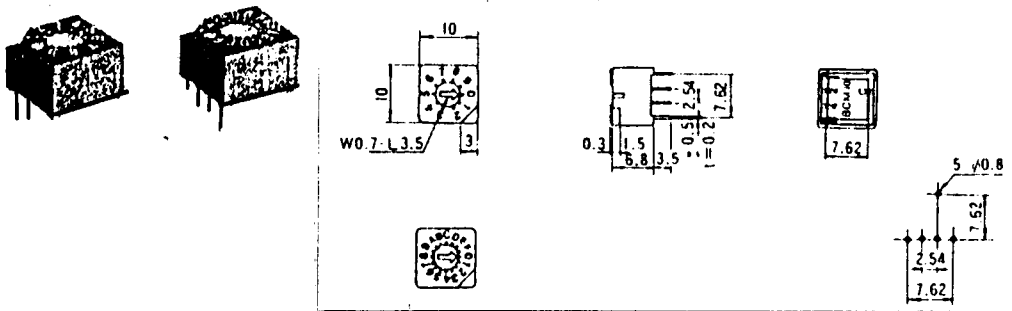

Flat type

SPECIFICATIONS:

Rating	DC 5 V 100mA
Contact resistance	100mΩ max.
Dielectric withstanding	AC250V for 1 min.
Insulation resistance	100MΩ min. (DC250V)
Rotation life	10,000 steps min.
Rotation torque	300gfcm
Operation temp.	-25° ~70℃
Construction	Perfectly sealed