
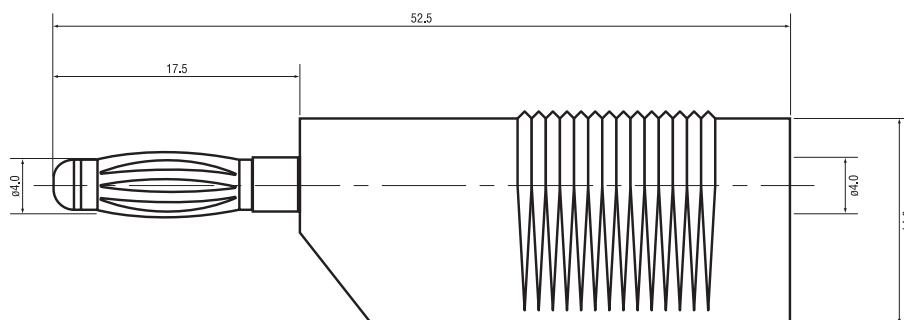


# TruConnect 4mm Stackable Test Plugs with Screw Termination

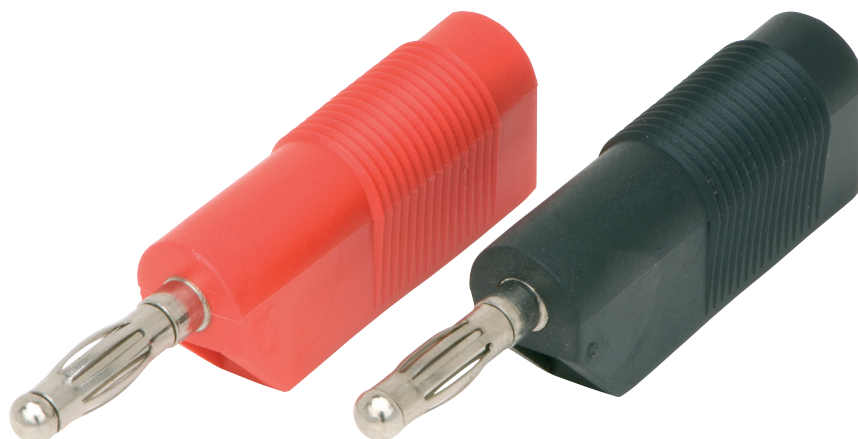

Stackable 4mm plug with the rigid insulating sleeve for self-assembly of test lead. Hexagonal body makes the connection more stable.

## Materials:

- Plug body: Brass
- Spring: Beryllium copper
- Surface treatment: Nickel
- Insulation: PE

## Ratings:

- Rated voltage & current: 30V AC-60V DC/max. 32A
- Max. cable diameters: 4mm
- Connection type: Solder or screw in

## Part Number Table:

Description	Order code
Plug, 4mm, Black	17-2641
Plug, 4mm Blue	17-2642
Plug, 4mm, Green	17-2643
Plug, 4mm, Red	17-2644
Plug, 4mm, Yellow	17-2645