
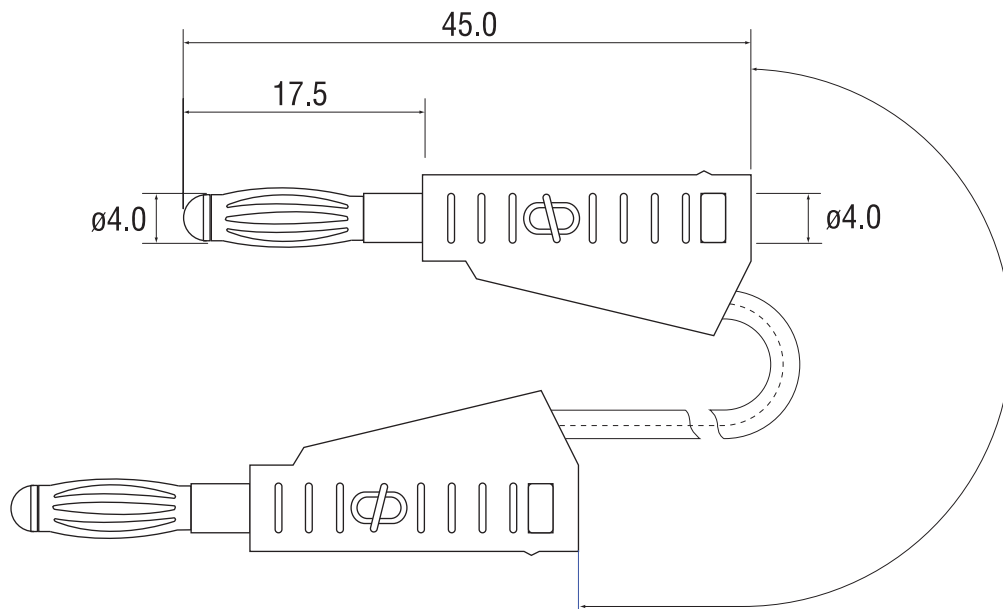


4mm Stackable Test Leads Length 500mm

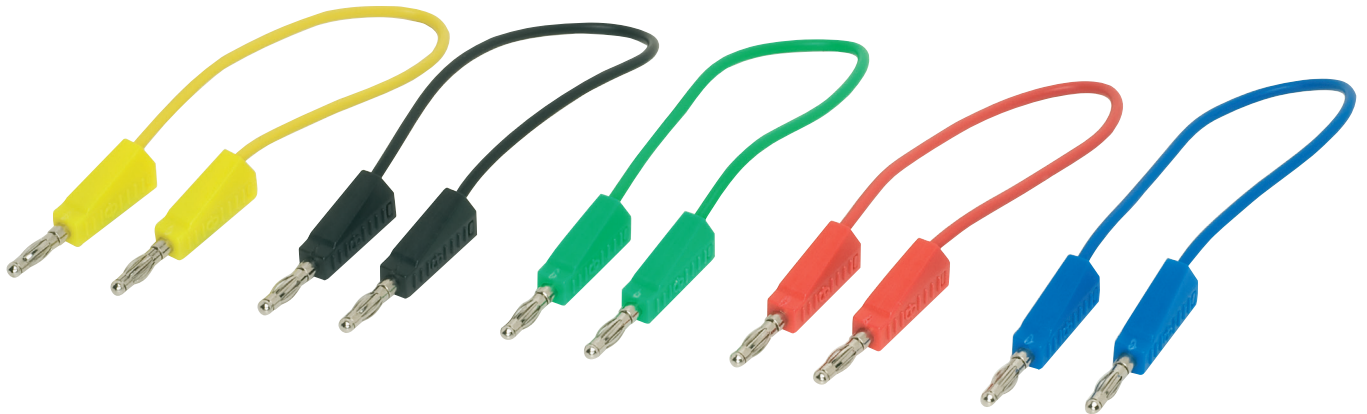

Flexible test lead with 4mm stackable plug.

Material:

- Surface treatment: nickel plated

Ratings:

- Rated voltage & current: 0.75mm²: 30V AC - 60V DC/max. 15A

Order code	Colour
17-2836	Black 4mm test lead
17-2837	Blue 4mm test lead
17-2838	Green 4mm test lead
17-2839	Red 4mm test lead
17-2840	Yellow 4mm test lead