


4mm Straight Plug to 4mm Right-angled Plug Test Leads

Black: **17-2843**

Red: **17-2844**

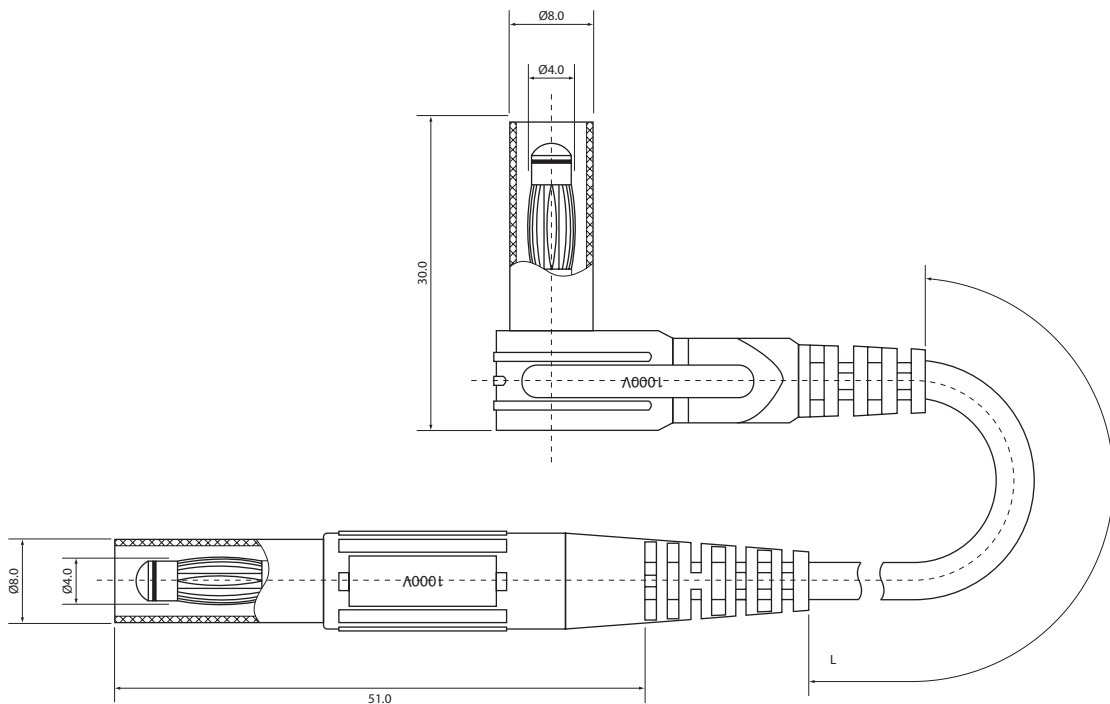

Flexible safety test lead with two 4mm straight plug and right angled plug.

Ratings:

Rated voltage & current:
0.75mm² 1000V/max. 19A
1.00mm² 1000V/max. 25A
2.50mm² 1000V/max. 32A