


# Product Specification PDF

Date	<b>Correct as of 6th Aug 2019</b>
Brand	<b>C.K</b>
Product	<b>T4334M 08</b>
Description	<b>Nut Spinner 8mm</b>
Barcode	<b>5013969533804</b>
Commodity code	<b>8205400000</b>
Country of origin	<b>DE</b>

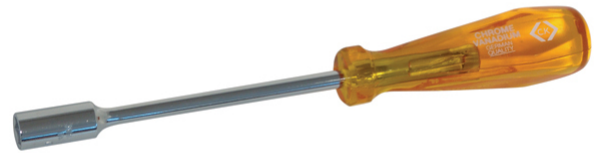

## Features & Benefits

~ Shatter resistant acetate handle ~ wipe clean, oil & acid resistant ~ Large square shape handle design for maximum torque ~ Handle injection moulded directly to blade giving the ultimate bond for increased reliability & durability ~ Anti roll flats to prevent the screwdriver rolling off sloping surfaces ~ Chrome plated toughened alloy steel blade for increased strength & durability ~ Precision machined tip for an exact screw fit & damage free screwdriving ~ Drop forged blades from Chrome Vanadium/Molybdenum steel, hardened and tempered ~ According to DIN 3125 ~ Size: 8 mm ~ Visible blade length: 100 mm ~ Overall length: 230 mm

## Applicable Standards

### Health & Safety

None applicable

### Warranty

C.K products are guaranteed for 1year against imperfect materials or workmanship. Damage caused through normal wear and tear or resulting from inappropriate use, is not covered.

## Product Weights and Measures

	Product only	Product & primary packaging	Secondary packaging	Transit packaging
Item Quantity	1	1	6	96
Width mm	27	45	95	300
Depth mm	27	30	330	350
Height mm	225	275	60	300
Weight	115	122	822	13.8
Packaging Information	Card use	0	Box	Case
	Card gms	0	90	675
	Plastic use	Hanger		-
	Plastic gms	7	-	0
	Metal use	0	0	-
	Metal gms	0	0	0
	Timber use	0	0	-
	Timber gms	0	0	0