

# INTERCHANGEABLE WALL PLUG POWER SUPPLY 9VDC 6WATT



## SW4456-H

### Features:

- Interchangeable AC Heads
- 1 Year Warranty
- Level VI Efficiency
- Worldwide Approvals



### Description:

The Stontronics range of 6 Watt Interchangeable wall plug power supplies provide 6 watts of continuous power with the flexibility of worldwide usage as they are supplied with UK, Euro, Auz & USA AC Heads , all Efficiency Level VI and carry worldwide safety approvals.


Specification	
Part Code	SW4456-H
Input Voltage Range	90-264 Vac
Input Frequency Range	47-63Hz
Input Current Rated	0.18A max.
Input AC Heads	UK, Euro, Auz & USA
Output Voltage Rating	9V
Output Current Rated	0.67A
Output Min Current	0.01A
Output Connection Type	2.1x5.5x12mm centre positive – Straight
Total Output Regulation	+/-5%
Line and Load Regulation	+/-5%
Ripple & Noise	200mVp-p
Efficiency	79.03% min
Over Voltage Protection	auto restart
Over Load Protection	auto restart
Operating Temperature	0°C to 40°C
Storage Temperature	-20°C to +80°C
Operating Humidity	10% to 90%
Storage Humidity	10% to 90%
Hi-Pot	3000Vac 10mA 1min
Leakage Current	<0.25mA max
Safety Standard	CE, TUV, C-Tick, cUL
EMI Standard	EN55022:2006+A1:2007/ EN6100-3-2 / EN6100-3-3
MTBF	50K Hours
Size mm max.	55 x 45 x 36mm
Weight	160g

# INTERCHANGEABLE WALL PLUG POWER SUPPLY 9VDC 6WATT



SW4456-H

## Diagrams

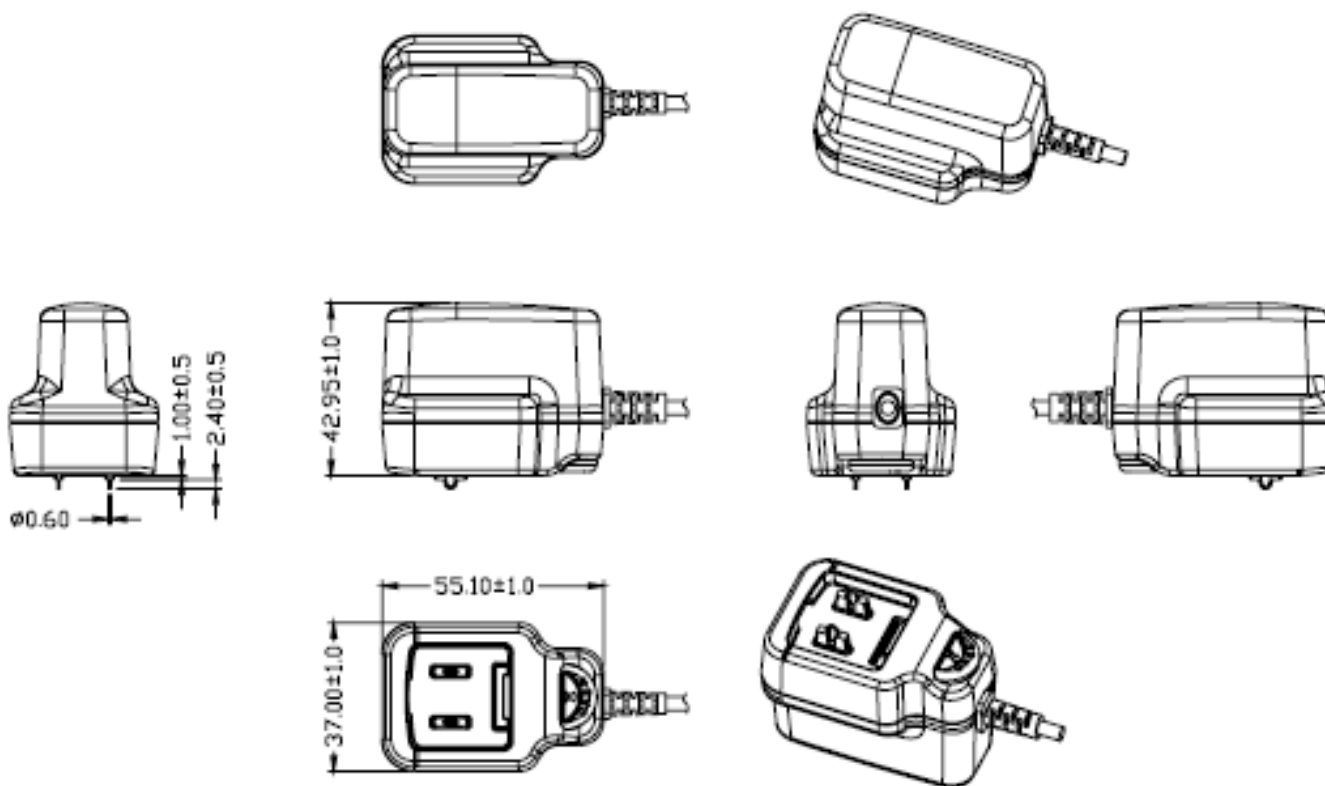

### General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.