

# UNITED KINGDOM 3-PIN PLUG-IN POWER SUPPLY 9VDC 15WATT



## SW3089-C2

### Features:

- United Kingdom Fixed AC Head
- 1 Year Warranty
- Level VI Efficiency
- CE Approved



### Description:

The Stontronics Range of Class II 15 watt AC/DC United Kingdom plug-in power supplies provide 15 watts of continuous power in a compact fixed wall plug enclosure suitable for use in many general power applications.

Specification	
Part Number	SW3089-C2
Input Voltage Range	90-264Vac
Input Frequency Range	50-60Hz
Input Current Rated	0.5A Max
Output Voltage Rating	+9V
Output Current Range	1.67A
Output Min Current	0A
Output Connection Type	2.1x5.5x12mm Centre Positive – Straight
Total Output Regulation	+/- 5%
Line and Load Regulation	+/- 5%
Ripple & Noise	150mVp-p
Efficiency	84.5% Min
Over Voltage Protection	25VDC Maximum
Over Load Protection	2.5A max with auto-recovery function
Operating Temperature	0 to 40°C
Storage Temperature	-20 to +60°C
Operating Humidity	20 to 85%
Storage Humidity	5 to 95%
Hi-Pot	3000VAC 10mA 1min
Leakage Current	0.25mA max
Safety Standard	Meet T-LICENSE(BS EN60950-1)
EMI Standard	Meet CE(EN55022)
MTBF	50k hours
Size mm max.	85(L) 43(W) 31 (H) mm
Weight	190g
Regulator Type	Switched Mode Power Supply

#### General Note


TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

# UNITED KINGDOM 3-PIN PLUG-IN POWER SUPPLY 9VDC 15WATT



SW3089-C2

## Diagrams

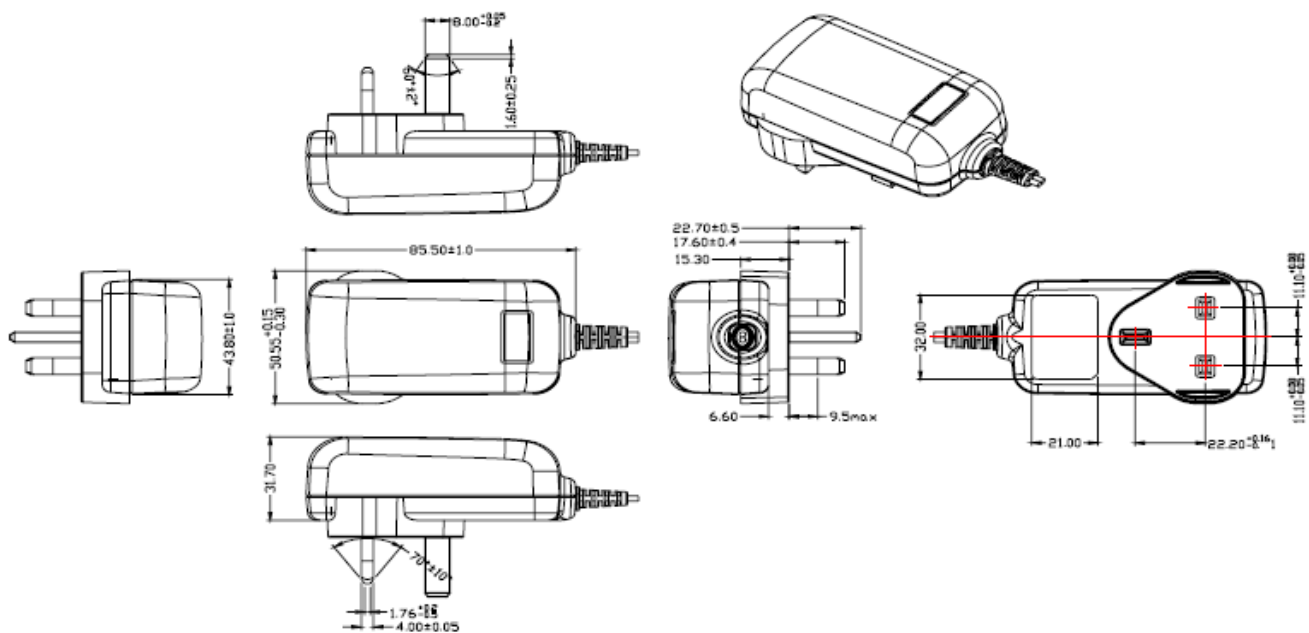

### General Note

TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

© TT Electronics plc

TT Electronics | Stontronics Ltd  
Chancerygate Business Centre, Cradock Road, Reading RG2 0AH, UK  
t: +44 (0) 118 931 1199

SL-004-110 ISS.0 27/11/2018 Page: 2