

UNITED KINGDOM 3-PIN PLUG-IN POWER SUPPLY 24VDC 24WATT

T6370ST



Features:

- United Kingdom Fixed AC Head
- 1 Year Warranty
- Level VI Efficiency
- CE Approved

Description:

The Stontronics Range of Class II 24 watt AC/DC United Kingdom plug-in power supplies provide 24 watts of continuous power in a compact fixed wall plug enclosure suitable for use in many general power applications.

Specification	
RS Stock Number	T6370ST
Input Voltage Range	90-264Vac
Input Frequency Range	47-63Hz
Input Current Rated	No Damage
Output Voltage Rating	+5V
Output Current Range	2.5A
Output Min Current	0A
Output Connection Type	2.1x5.5x12mm Centre Positive – Right Angle
Total Output Regulation	+/- 5%
Line and Load Regulation	+/- 2%
Ripple & Noise	300mVp-p
Efficiency	80.59% Min
Over Voltage Protection	10VDC Maximum
Over Load Protection	5A max with auto-recovery function
Operating Temperature	0 to 40°C
Storage Temperature	-20 to +60°C
Operating Humidity	20 to 85%
Storage Humidity	5 to 95%
Hi-Pot	3000VAC 10mA 1min
Leakage Current	0.25mA max
Safety Standard	Meet T-LICENSE(BS EN60950-1)
EMI Standard	Meet CE(EN55022)
MTBF	50K Hours
Size mm max.	70 (L) 50 (W) * 77(H) mm
Weight	120 g
Regulator Type	Switched Mode Power Supply

General Note


TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

TT Electronics | Stontronics Ltd
Chancerygate Business Centre, Cradock Road, Reading RG2 0AH, UK
t: +44 (0) 118 931 1199

UNITED KINGDOM 3-PIN PLUG-IN POWER SUPPLY 24VDC 24WATT

T6370ST

Diagrams

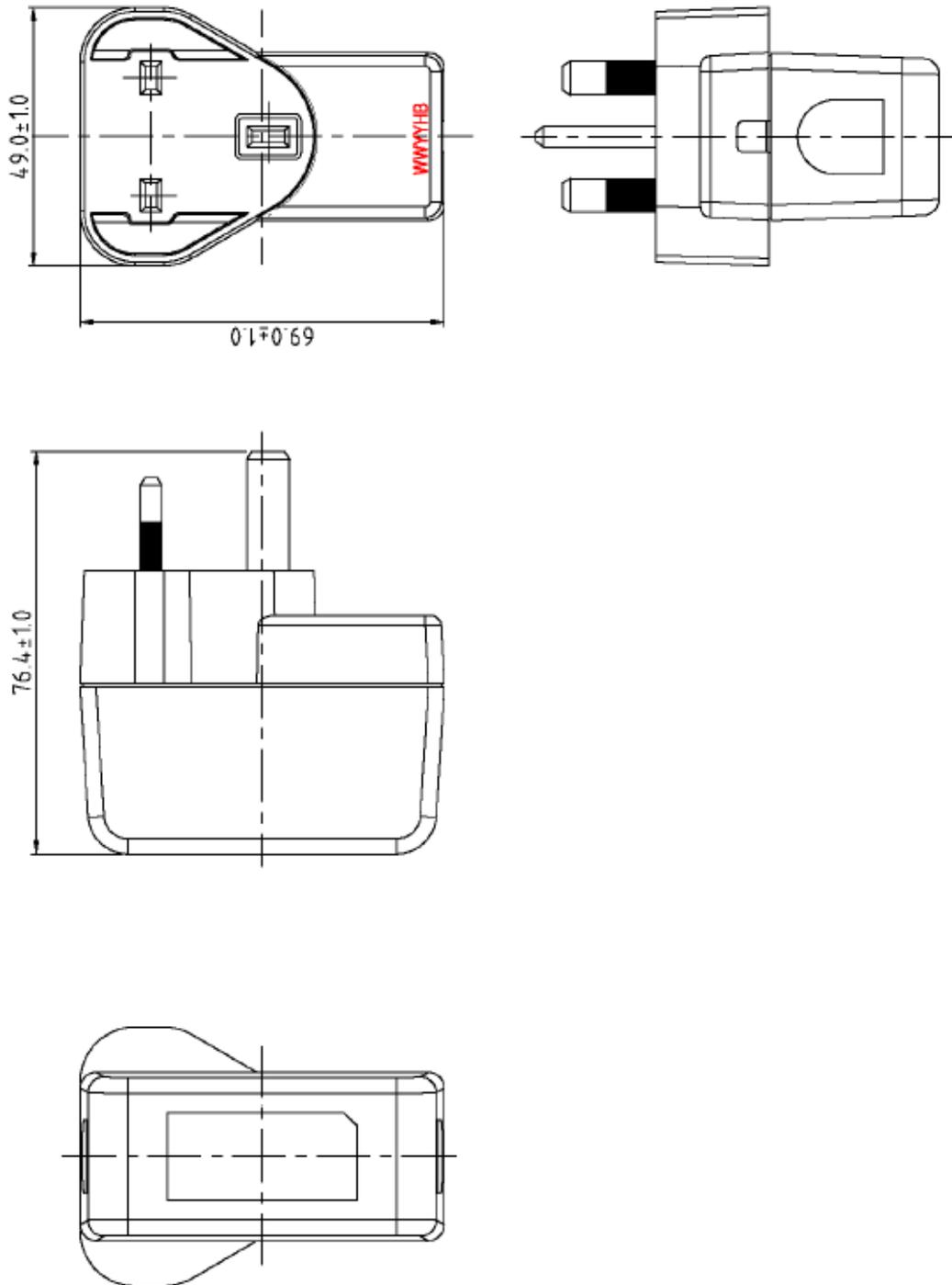

General Note
TT Electronics reserves the right to make changes in product specification without notice or liability. All information is subject to TT Electronics' own data and is considered accurate at time of going to print.

TT Electronics | Stontronics Ltd
Chancerygate Business Centre, Cradock Road, Reading RG2 0AH, UK
t: +44 (0) 118 931 1199