

LF-3200 SOLDERING STATION




RoHS conform




Humanism interface:
The angle of control panel is conform to humanism .It's easy to read and set



Full ardal body:
Conveyance security, sturdy and durable, equipent longer duration

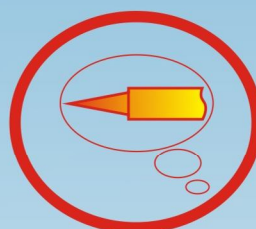

High frequency heater:
Temperature climbs fast, favored by lead free soldering

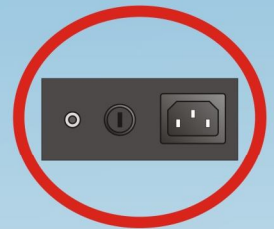

Build-up grounding:
Can link up ESD wrist strap

Product Features:

Password lock: Convenient for control

Auto sleep: Save power and the life of tip

Auto sleep: Save power and the life of tip

Mintype station: Less desktop occupation


Quick heat: Room temperature to 350 C time taken 13s

Real-temp modification: Real temperature can modify Manually

Sensor fail notification: When the sensor failed, "S-E" will Be shown, SIA will power off

Heater fail notification: When the heater failed, "H-E" will Be shown, SIA will power off

Heating curve determination:

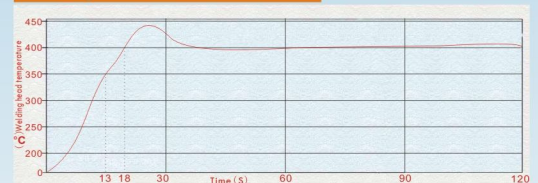

SPECIFICATION:

Input power	100-120Vac 60Hz 220-240Vac 50Hz
Wattage	120W
Temperature range	100-520 °C 212-968 °F
Standard tip	44-413068



XYTRONIC CO.,LTD
<http://www.xytronic.com>