



Material number	0 601 072 070
EAN	3165140547987
Baretool number	3601K72070
4 x 1.5 V AAA	✓
Carrying strap 2 609 170 085	✓
Manufacturer's certificate	✓
Protective bag	✓



Technical data

Technical data

Laser diode	635 nm, < 1 mW
Measurement range	0,05 – 150
Laser class	2
Measurement accuracy, typical	± 1 mm
Measurement time, typical	< 0.5 s
Measurement time, max.	4 s
Power supply	4 x 1.5 V LR03 (AAA)
Automatic deactivation	5 min.
Weight, approx.	0.24 kg
Length	120 mm
Width	66 mm
Height	37 mm
Units of measurement	m/cm/mm
Memory capacity (values)	30
Battery lifetime, individual measurements, approx.	30.000
Battery lifetime, operating time, approx.	5 h
Dust and splash protection	IP 54

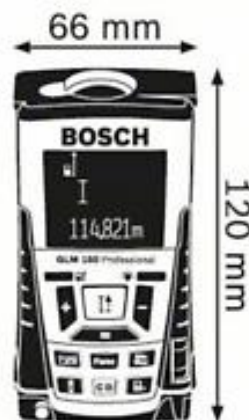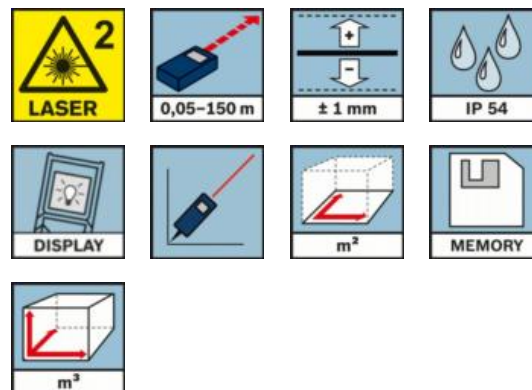

Functions

Timer function	✓
----------------	---

Sales information

Positioning

- More functionality and user-friendliness for indoor work

User benefit

- New functions such as partial height measurement, height calculation and roof slope measurement
- Millimetre-accurate measurement of areas, volumes and distances up to 150 m
- Easy handling, intuitive user interface and large, illuminated 4-line display

Other features

- Maximum precision over the entire lifetime due to tough ceramic optics carrier
- IP54: dust and splash protection for the complete tool including battery compartment
- Multifunctional measuring pin for precise measurement from hard-to-reach areas and edges
- Storage of the last 30 measurements