

Product information

86 05 250 T

Pliers Wrench

Pliers and a wrench in a single tool



- Replaces the need for sets of metric and imperial spanners
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Pliers with tether attachment point for mounting a fall protection
- Also excellent for gripping, holding, pressing and bending workpieces
- Smooth jaws for damage free installation of plated fittings - working directly on chrome!
- Zero backlash jaw pressure prevents damage to edges of sensitive components
- Fast adjustment by pushing a button directly on the workpiece
- No unintentional shift of the gripping jaws and no slipping of the joint
- Replaces the need for sets of metric and imperial spanners
- Parallel jaws give a more solid grip; its design allows flexible adjustment of all widths up to the specified maximum size
- The ratchet type principle allows quick and easy tightening and release of all bolted connections
- Lever transmission greater than 10 : 1 for strong gripping power
- Chrome vanadium electric steel, forged, oil-hardened




General

Article No.	86 05 250 T
EAN	4003773080138
Pliers	chrome plated
Head	chrome plated
Handles	with multi-component grips, with integrated tether attachment point for a tool tether
weight	500 g
Dimensions	250 x 58 x 23 mm
Reach	no
RohS	no

Technical details

	8.0 mm
Joint thickness (B3)	14.0 mm
Tips thickness (B1)	8.0 mm
Adjustment positions	19
Capacities for nuts	2
Capacities for nuts	52 mm

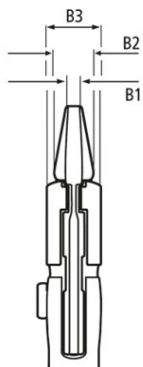



Classification

eCl@ss 5.1.4	21043826
proficl@ss 6.0	AAA936c004
UNSPSC 13.1	27112112

Accessories

86 09 250 V01	Protective jaws for 86 XX 250 3 pairs
---------------	---

technical change and errors excepted