

## Product information

# 95 62 190 T

## Wire Rope Cutter

Forged



### Double function: neat cutting, precise crimping

- Pliers with tether attachment point for mounting a fall protection
- With two crimping dies for end caps on Bowden cable sheaths and end ferrules for traction cables
- Comfortable work thanks to handy, slim design and internal opening spring
- Bolted joint for precise blade guidance, re-adjustable
- High leverage for reduced effort
- Cutting edge hardness approx. 64 HRC
- Chrome vanadium heavy-duty steel, forged, multi stage oil-hardened




General	
Article No.	95 62 190 T
EAN	4003773080206
Head	burnished
Handles	with multi-component grips, with integrated tether attachment point for a tool tether
weight	345 g
Dimensions	190 x 66 x 24 mm
Reach	Nein
RohS	no

Technical details	
Cutting capacities piano wire (diameter)	Ø 2.5 mm
Cutting capacity copper cable, multiple-stranded (diameter)	Ø 7.0 mm
Cutting capacities wire rope (diameter)	Ø 5.0 mm
Cutting capacities medium hard wire (diameter)	Ø 4.0 mm
AWG	8
Drop Protection System	yes

Classification	
eCl@ss 5.1.4	21040601
proficl@ss 6.0	AAC479c002
UNSPSC 13.1	23241616

technical change and errors excepted

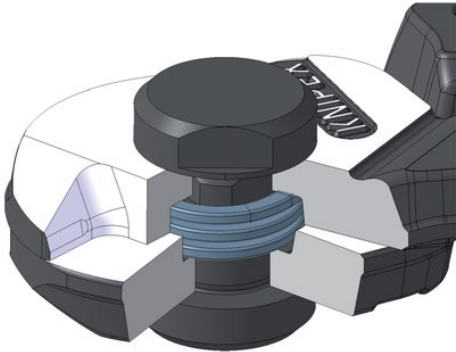

Internal opening spring