


440.6 440 - Metric combination wrenches

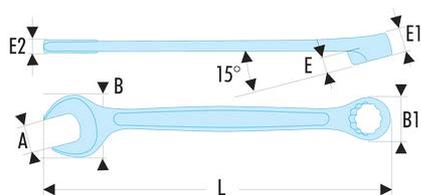

Description:

- Standard wrench for all current applications.
- High mechanical strength combined with compact size meeting aeronautical standards.
- Ring head:
 - Ring open end (size E) designed for better access to series or embedded screws.
 - OGV® profile with 12-point ring for powerful tightening while protecting the nut. H suffix = 6-point ring.
 - Ring head angled at 15°.
- Open end head:
 - Open end angled at 15°.
 - Open end head-handle geometry optimised for increased access.
- Metric sizes: 4 to 41 mm.
- Presentation: satin chrome finish.

A [mm]: 6

B [mm]: 14,1

B1 [mm]: 10,0

C1 [mm]: 6,0

E [mm]: 3,1

E1 [mm]: 6,0

E2 [mm]: 3,8

L [mm]: 115

[g]: 20