


## V.445F Straight die grinder - 6 mm collet front exhaust

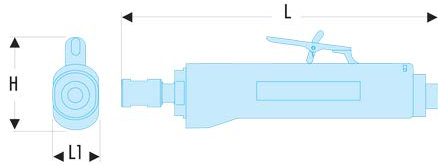

### Description:

- High power motor at 1HP gives you the best productivity.
- Composite handle reduces weight and insulates.
- Front exhaust design blows the air on the workplace to clean it up.
- Industrial grade 6 mm collet for durability.
- Feather teasing trigger for optimum control.
- Free speed 20000 tr/min.
- Power 1 cv.
- Collet capacity 6 mm.
- Working pressure 6,2 bar.
- Average air consumption 180 l/min.
- Air inlet 1/4".
- Minimum hose diameter 10 mm - 3/8".
- Vibration <math><2,50\text{ m/s}^2/\text{a}</math>.
- Vibration 1,50 m/s<sup>2</sup>/K.
- Sound pressure 90,11 dB(A).
- Sound power 101,11 dB(A).

---

H [mm]: 80

---

L [mm]: 207

---

L1 [mm]: 43

---

[g]: 960

---