


Powerful, Affordable Rechargeable LED Work Light



Simple operation
Click button to set light mode

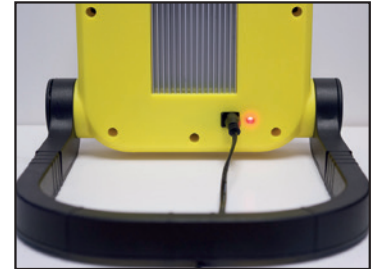

Galaxy-1000 battery charging indicator

Key features:

- 2 Light modes: 1000 lumens (HIGH) - 500 lumens (HALF)
- Runtime: 1.4 hours (HIGH) - 3.2 hours (HALF)
- Up to 10m flood beam
- Rechargeable Li-ion work light
- Designed to meet IP54
- Battery 7.4V Lithium-ion 1800mAh
- Fold flat design for compact storage
- Supplied with: 230V AC + Vehicle charger
- High impact ABS housing and shatterproof polycarbonate lens
- Can be wall/tripod mounted




Handle and stand



GALAXY 1000



7.4V
1800mAh

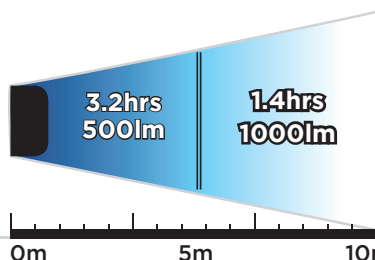

4HRS CHARGE TIME

Light coverage

0m 5m 10m

Optional Accessories:
• 1.7m Tripod



PRODUCT CODE	DESCRIPTION
SPTRIPOD1.7	1.7M TRIPOD

PRODUCT CODE	DIMENSIONS
NSGALAXY1000	(L)193.5x(W)230.4x(D)63.3mm