



Key features:

- Light Power 1000 lumens
- 600 metre spot beam
- 6 light modes: 100%/60%/30%/5%/Strobe/SOS
- 2 Hidden light modes: Strobe/SOS
- 2 switches - Tail cap tactical and body
- Through switch battery status indicator
- Bright CREE XLAMP XML U2 LED lights
- Secure grip
- 3.7V, 2600mAh Li-ion battery
- Type III anodised Aluminium housing



 **USB Rechargeable**



1000



600
Metres



50
Max Hours



1.5 Metre
Impact
Resistance



IPX7



6 Hours
Charging
Time



3.7V 2600mAh
Li-ion Battery



USB
Rechargeable



On/off switch indication:
Battery + Charging Status


Powered by
Rechargeable
LI-ION
Technology

Supplied with:

- USB Charging cable

Optional Accessories:

- AC Mains charger
- Vehicle charger
- Red cone
- Pocket clip
- Holster

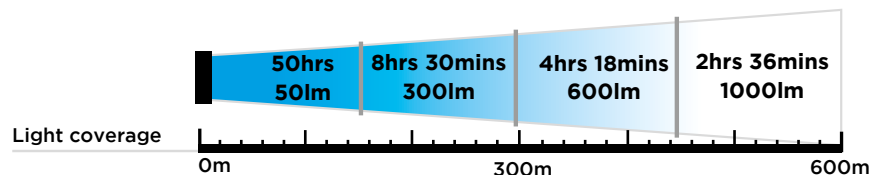

PRODUCT CODE	DIMENSIONS	WEIGHT
NSEXPLORER1000	(L)70x(W)22.5x(D)44mm	200g