

# EX325



## Zone 0 • 1 • 2 • M1 ATEX Right Angle Hand Torch

2 Light modes:

High 323lm

Low 140lm

 


Gas pressure  
release valve

On/off switch



Powered  
by 4x



CREE XP-G LEDs  
270lm output

Stainless steel  
belt/pocket clip



Rubberised handle  
for comfortable  
grip



INTRINSICALLY SAFE  
LED HEAD TORCH FOR  
USE IN ZONE 0  
HAZARDOUS AREA

### Key features:

- Intrinsically safe LED right angled torch for use in Zone 0 hazardous areas
- Up to 290 | 184 Metre beam
- High powered LED - CREE XP-G
- MINING - Ex ia I Ma
- Powered by 4x AA batteries
- Drop proof up to 1m
- Design to meet IP54
- Easy to use, maintenance free
- Aluminium heat sink enhancing LED efficiency



IECEX




RoHS



### NSEX325 Certifications:

|       |   |
|-------|---|
| CSA   | CLASS I DIV 1 & 2 GRP ABCD<br>CLASS II DIV 1 & 2 GRP EFG<br>CLASS III     |
| ATEX  | EX I M1 Ex ia   Ma,<br>EX II 1G Ex ia IIC T4 Ga                           |
| IECEX | GAS: Ex ia Ma, Ex ia IIC T4 Ga<br>MINE: Ex: Ia   Ma<br>IECEX SIR 15.0062x |
| Reach | Approved  |
| RoHS  | Approved  |
| CE    | Approved  |

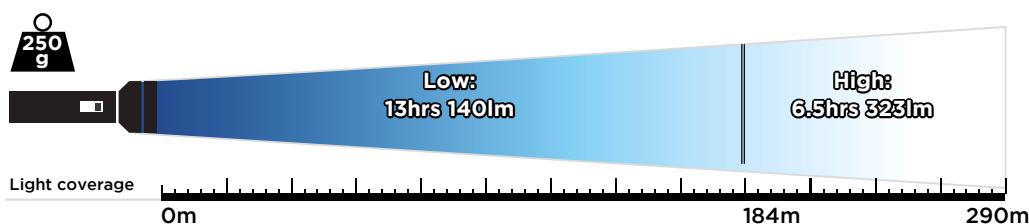

NSEX325

| PRODUCT CODE | DIMENSIONS           |
|--------------|----------------------|
| NSEX325      | (L)183x(w)69x(w)63mm |