



|                        |               |                               |              |
|------------------------|---------------|-------------------------------|--------------|
| <b>EAN:</b>            | 4013288184078 | <b>Size:</b>                  | 157x13x13 mm |
| <b>Part number:</b>    | 05030413001   | <b>Weight:</b>                | 19 g         |
| <b>Article number:</b> | 1569 ESD      | <b>Country of origin:</b>     | CZ           |
|                        |               | <b>Customs tariff number:</b> | 82054000     |

- Kraftform Micro screwdriver for hexagon head screws
- ESD-safe tool thanks to surface resistance of  $\leq 10^9$  Ohm
- Multi-component Kraftform Micro handle for fast and ergonomic screwdriving
- Kraftform Micro handle with swivel cap for rapid twisting
- Take it easy tool finder: colour coding according to profile and size
- Hexagonal anti-roll feature against rolling away

ESD-safe Micro screwdriver. Dependable protection against electrostatic energy and associated damage. Rapid twisting results from fixing the hand on the head and using the fast-turning zone just below. This makes time-consuming grip adjustments unnecessary. Power zones with integrated soft sections ensure the transfer of high loosening and tightening torque; a precision zone for the right rotation angle during fine adjustment work. "Take it easy" tool finder with colour coding according to profiles and size stamp - for simple and rapid accessing of the required tool.



#### Web link

[https://products.wera.de/en/screwdrivers\\_esd\\_series\\_1569\\_esd.html](https://products.wera.de/en/screwdrivers_esd_series_1569_esd.html)

Wera - 1569 ESD  
 05030413001 - 4013288184078

Wera Werkzeuge GmbH  
 Korzter Straße 21-25  
 D-42349 Wuppertal  
 Tel: +49 (0)2 02 / 40 45-0  
 E-Mail: [info@wera.de](mailto:info@wera.de)

### Wera ESD Tools



The requirements for ESD-safe screwdrivers are specified in the European standard DIN EN 61340-5-1. This standard also includes a handle that has to be out of a defined conductive material. The Wera products in the ESD series satisfy these standards and the even more stringent requirements demanded by some technology companies.

### High protection




The electric surface resistance of the Wera ESD material is  $\leq 10^9$  ohm. This securely protects components against electrostatic energy and associated damage.

### Kraftform Micro handle




Multi-component screwdriver handle for ergonomic working.

### The precision zone

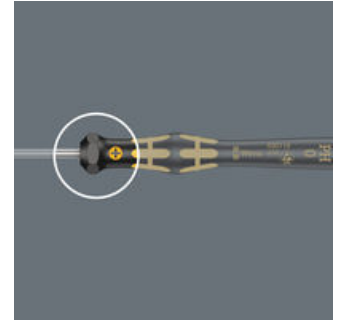

The precision zone directly above the blade gives the user a better feel for the right rotation angle during fine adjustment work.

### The power zone

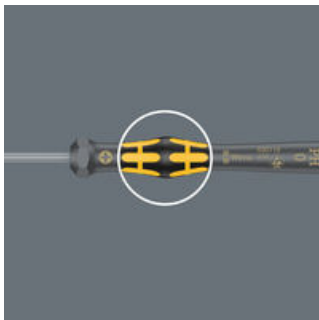


The power zone has integrated soft zones near the blade tip to ensure high torque transfer for loosening or tightening screws without losing contact with the screw.

### Rotating cap and fast-turning zone



The fast-turning zone just below the rotating cap allow rapid twisting. This makes time-consuming grip adjustments as with other conventional precision screwdrivers unnecessary.

### "Take it easy" Tool Finder

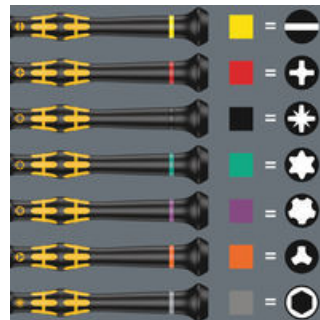

Screwdrivers with "Take it easy" tool finder: colour coding according to profile and size stamp.

### Web link

[https://products.wera.de/en/screwdrivers\\_esd\\_series\\_1569\\_esd.html](https://products.wera.de/en/screwdrivers_esd_series_1569_esd.html)

Wera - 1569 ESD

05030413001 - 4013288184078

Wera Werkzeuge GmbH

Korzer Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: [info@wera.de](mailto:info@wera.de)

Further versions in this product family:

|                    |  | <br>mm | <br>mm | <br>mm | <br>inch |
|--------------------|-----------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------|-----------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------------|---------------------------------------------------------------------------------------------|
| 05030410001        | 1.5                                                                               | 60                                                                                      | 97                                                                                      | 5.7                                                                                       | 2 3/8"                                                                                      |
| 05030411001        | 1.8                                                                               | 60                                                                                      | 97                                                                                      | 5.7                                                                                       | 2 3/8"                                                                                      |
| 05030412001        | 2.0                                                                               | 60                                                                                      | 97                                                                                      | 5.7                                                                                       | 2 3/8"                                                                                      |
| <b>05030413001</b> | <b>2.5</b>                                                                        | <b>60</b>                                                                               | <b>97</b>                                                                               | <b>5.7</b>                                                                                | <b>2 3/8"</b>                                                                               |
| 05030414001        | 3.0                                                                               | 60                                                                                      | 97                                                                                      | 5.7                                                                                       | 2 3/8"                                                                                      |
| 05030415001        | 3.2                                                                               | 60                                                                                      | 97                                                                                      | 5.7                                                                                       | 2 3/8"                                                                                      |
| 05030416001        | 3.5                                                                               | 60                                                                                      | 97                                                                                      | 5.7                                                                                       | 2 3/8"                                                                                      |
| 05030417001        | 4.0                                                                               | 60                                                                                      | 97                                                                                      | 5.7                                                                                       | 2 3/8"                                                                                      |
| 05030418001        | 4.5                                                                               | 60                                                                                      | 97                                                                                      | 6.4                                                                                       | 2 3/8"                                                                                      |
| 05030150001        | 5.0                                                                               | 60                                                                                      | 97                                                                                      | 7.0                                                                                       | 2 3/8"                                                                                      |
| 05030151001        | 5.5                                                                               | 60                                                                                      | 97                                                                                      | 7.8                                                                                       | 2 3/8"                                                                                      |

## Web link

[https://products.wera.de/en/screwdrivers\\_esd\\_series\\_1569\\_esd.html](https://products.wera.de/en/screwdrivers_esd_series_1569_esd.html)

Wera - 1569 ESD

05030413001 - 4013288184078

Wera Werkzeuge GmbH

Korzerter Straße 21-25

D-42349 Wuppertal

Tel: +49 (0)2 02 / 40 45-0

E-Mail: [info@wera.de](mailto:info@wera.de)