

Click-Torque Lock C 3 Torque wrench, adjustable, reversible ratchet, Torque Lock function, 40-200 Nm, 1/2" x 40-200 Nm

Click-Torque Lock series - adjustable torque wrenches with Torque Lock function



EAN:	4013288234193	Size:	540x60x60 mm
Part number:	05075692001	Weight:	1600 g
Article number:	Click-Torque Lock C 3	Country of origin:	TW
		Customs tariff number:	82041100

- With 1/2" square head drive
- Torque Lock function: The torque function can be deactivated so that the tool can also be used for loosening
- Extra click: audible and tactile torque setting
- Torque wrench gives an audible and tactile signal
- Measuring range: 40-200 Nm; precision $\pm 3\%$ as per DIN EN ISO 6789-1:2017-07

Adjustable torque wrench for controlled clockwise torque operation. With 1/2" square head drive. The torque function can be deactivated (Torque Lock function), so that the tool can also be used for loosening. Easy setting and saving of the default value. The audible and tactile clicks on reaching the scale values facilitate the safe setting of the desired torque value. The robust release mechanism guarantees a clearly audible and tactile release signal when the set torque value is reached. Fine-toothed reversible ratchet with 45 teeth. Accuracy of $\pm 3\%$ as per DIN EN ISO 6789-1:2017-07.



Web link

https://products.wera.de/en/new_products_2025_click-torque_lock_series_-_adjustable_torque_wrenches_with_torque_lock_function_click-torque_lock_series_-_adjustable_to

Wera - Click-Torque Lock C 3
05075692001 - 4013288234193

Wera Werkzeuge GmbH
Korzerter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

Click-Torque Lock C 3 Torque wrench, adjustable, reversible ratchet, Torque Lock function, 40-200 Nm, 1/2" x 40-200 Nm
Click-Torque Lock series - adjustable torque wrenches with Torque Lock function



Torque Lock function



Click-Torque Lock Torque wrench with Torque Lock function. Make Torque easy.



The torque function can be deactivated so that the tool can also be used for loosening.

With external square head tip



1/2" external square (including patent-registered socket locking).

Exact



Precision of ±3 % as per DIN EN ISO 6789-1:2017-07.

Easy and safe




Easy setting and saving of the desired torque value; easy to read on main and fine scales.

Setting with Speed



With audible and tactile locking when the scale values are reached.

Release mechanism

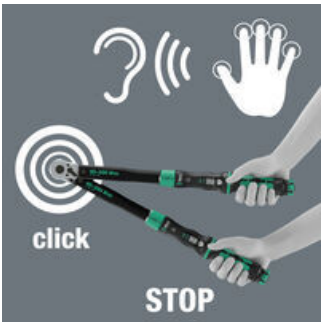

On reaching the desired torque value, an audible and tactile mechanism is triggered.

Further versions in this product family:

															
	inch	Nm	Nm	lbf. ft.	mm	mm	mm	mm	mm	inch	inch	inch	inch	inch	inch
05075692001	1/2"	40-200	1.0	30-146	512	140	47	43	18.4	20 5/32"	5 1/2"	1 27/32"	1 11/16"	23/32"	

Web link

https://products.wera.de/en/new_products_2025_click-torque_lock_series_-_adjustable_torque_wrenches_with_torque_lock_function_click-torque_lock_series_-_adjustable_to

Wera - Click-Torque Lock C 3
05075692001 - 4013288234193

Wera Werkzeuge GmbH
Korzelter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de