

Click-Torque Lock C 3 R/L Torque wrench, adjustable, Torque function, square head insert (1/2"), clockwise/counterclockwise torque operation, 40-200 Nm, 1/2" x 40-200 Nm

Click-Torque Lock R/L series - adjustable torque wrenches with Torque Lock function



EAN:	4013288233660	Size:	540x60x60 mm
Part number:	05075695001	Weight:	1600 g
Article number:	Click-Torque Lock C 3 R/L	Country of origin:	TW
		Customs tariff number:	82041100

- For clockwise and counterclockwise operation
- Torque Lock function: The torque function can be deactivated so that the tool can also be used for loosening
- With square head insert (including patent-registered socket locking)
- Extra click: audible and tactile torque setting
- Torque wrench gives an audible and tactile signal
- Measuring range: 40-200 Nm; precision $\pm 3\%$ as per DIN EN ISO 6789-1:2017-07

Adjustable torque wrench for controlled clockwise and counterclockwise torque operation. With 1/2" square head drive. The torque function can be deactivated (Torque Lock function), so that the tool can also be used for loosening. Easy setting and saving of the default value. The audible and tactile clicks on reaching the scale values facilitate the safe setting of the desired torque value. The robust release mechanism guarantees a clearly audible and tactile release signal when the set torque value is reached. Fine-toothed reversible ratchet with 45 teeth. Accuracy of $\pm 3\%$ as per DIN EN ISO 6789-1:2017-07.



Web link

https://products.wera.de/en/new_products_2025_click-torque_lock_series_-_adjustable_torque_wrenches_with_torque_lock_function_click-torque_lock_r_l_series_-_adjustable

Wera - Click-Torque Lock C 3 R/L
05075695001 - 4013288233660

Wera Werkzeuge GmbH
Korzelter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de

Click-Torque Lock C 3 R/L Torque wrench, adjustable, Torque function, square head insert (1/2"), clockwise/counterclockwise torque operation, 40-200 Nm, 1/2" x 40-200 Nm

Click-Torque Lock R/L series - adjustable torque wrenches with Torque Lock function

Torque Lock function



The torque function can be deactivated so that the tool can also be used for loosening.

With external square head tip



With square head insert (including patent-registered socket locking) for controlled clockwise and counterclockwise torque operation.

Exact



Precision of $\pm 3\%$ as per DIN EN ISO 6789-1:2017-07.

Easy and safe



Easy setting and saving of the desired torque value; easy to read on main and fine scales.

For right and left direction




The Click-Torque torque wrench is suitable for clockwise and counterclockwise torque operation. Very smooth change of direction thanks to captive square head insert.

Setting with Speed



With audible and tactile locking when the scale values are reached.

Release mechanism

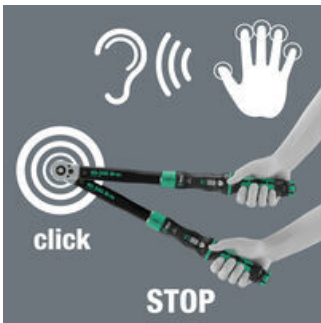

On reaching the desired torque value, an audible and tactile mechanism is triggered.

Further versions in this product family:

														
	inch	Nm	Nm	lbf. ft.	mm	mm	mm	mm	mm	inch	inch	inch	inch	inch
05075695001 ¹⁾	1/2"	40-200	1.0	30-146	512	140	47	43	18.4	20 5/32"	5 1/2"	1 27/32"	1 11/16"	23/32"

¹⁾ Available from September 2025

Web link

https://products.wera.de/en/new_products_2025_click-torque_lock_series_-_adjustable_torque_wrenches_with_torque_lock_function_click-torque_lock_r_l_series_-_adjustable

Wera - Click-Torque Lock C 3 R/L
05075695001 - 4013288233660

Wera Werkzeuge GmbH
Korzerter Straße 21-25
D-42349 Wuppertal
Tel: +49 (0)2 02 / 40 45-0
E-Mail: info@wera.de