

IRWIN®

Utility Knives & Blades

TRAPEZOID BI-METAL BLUE SAFETY BLADES



TRAPEZOID BI-METAL BLUE SAFETY BLADES

SHARPER. SAFER. BETTER.



LASTS 3X LONGER*
more cuts for your money



SHATTERPROOF
for ultimate safety



SAFER
NOT POINTED™
SAFETY
shaped safety points
to reduce risk



UNIVERSAL USE
ideal for most
applications

TRAPEZOID BI-METAL BLUE SAFETY BLADES

FEATURES

1. SHATTERPROOF

the spring steel backing combined with dual hardening of the blade makes our blade more durable, and shatterproof

2. 3x LONGER LIFE*

due to the High Speed Steel edge the blade stays sharper up to 3 times longer

3. REDUCE ACCIDENTS

reduce the risk of accidental direct puncture wounds

4. EXCELLENT PENETRATION


perpendicular blade junction gives excellent blade penetration

5. FITS MOST KNIVES

the two notch blade design fits most utility knives

6. CUTS THE TOUGHEST MATERIALS

great for cutting dry lining, insulation, flooring, roofing and more

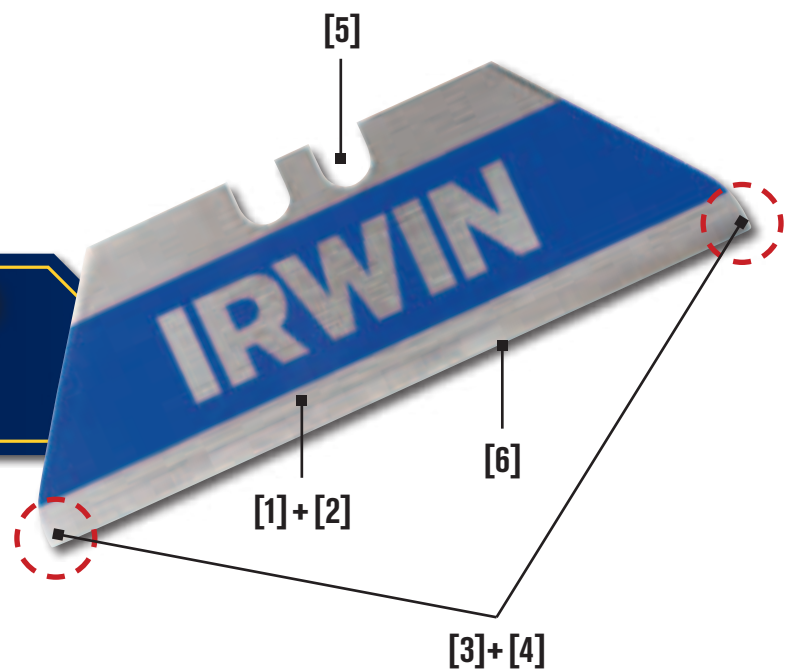

ITEM NO.	DESCRIPTION	EAN	SHelf PACK
10505823	BI-METAL "BLUE" SAFETY TRAP BLADE 5PK	5706915058239	5
10505824	BI-METAL "BLUE" SAFETY TRAP BLADE 50PK	5706915058246	1

*versus traditional IRWIN carbon blades