

# IRWIN®

NEW

## The longest lasting flat bit EVER

**BLUE  
GROOVE  
POWER**



LONG-LASTING  
**BiMetal**  
TECHNOLOGY®

↑  
**TOUGHER  
THAN  
NAILS**



\* vs basic flat bits  
\*\* 50 times life versus main competitors  
(in nail embedded wood, tested in 2009)

## BLUE GROOVE POWER!



### EXTREME DURABILITY

High speed steel cutting edges provide long life in tough applications, for extreme durability and nail cutting.

### COMPACT LENGTH

Designed to fit between studs in most common cordless drills.

LONG-LASTING




**SELF-FEEDING**  
Self-feed tip pulls bit through material.

### FAST, CLEAN CUTTING

3 cutting edges enhance chip removal for a fast, clean hole and 6 x faster than a standard flat bit.

**CARBON STEEL BODY**  
for Flexibility.

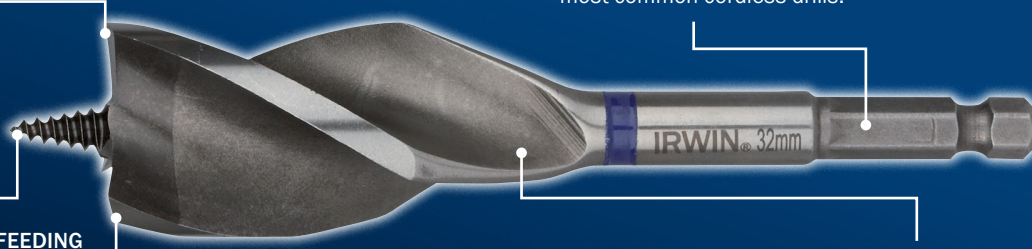

Item #	Description	EAN number
10507712	Blue Groove Power 14mm	5706915077124
10507713	Blue Groove Power 16mm	5706915077131
10507714	Blue Groove Power 18mm	5706915077148
10507715	Blue Groove Power 20mm	5706915077155
10507716	Blue Groove Power 22mm	5706915077162
10507717	Blue Groove Power 25mm	5706915077179
10507718	Blue Groove Power 28mm	5706915077186
10507719	Blue Groove Power 32mm	5706915077193
10507720	Blue Groove Power 3 pcs set (14,16,18mm)	5706915077209
10507764	Blue Groove Power 3 pcs set (20,22,25mm)	5706915077643