

IRWIN. VISE-GRIP®

Locking Tools

Featuring
Fast Release™
Locking Tools



IRWIN® VISE-GRIP®



The Professionals Choice Since 1924

The VISE-GRIP® Locking Tool was invented in 1924 by a blacksmith in the small town of DeWitt, Nebraska. Eight decades and more than a half-billion tools later, IRWIN® VISE-GRIP continues to be handcrafted in the U.S.A with the same quality and dependability that trade professionals have trusted and preferred since the beginning.

Our expertise in design and manufacturing produces locking tools with more than **twice the life** and **significantly more strength** than other tools on the market. And to further meet the needs of professional tool users, IRWIN VISE-GRIP is now available in three handle configurations: The Original™, ProTouch™ and Fast Release™.



A Perfect Grip for Any Job

The Original SINCE 1924™

The Original IRWIN VISE-GRIP Locking Tools provide powerful locking force using the classic triggered design.



ProTouch™ GRIPS

IRWIN VISE-GRIP ProTouch Locking Tools provide a cushioned handle and rugged grip for all of your toughest jobs. The cushioned grip reduces vibration, hand fatigue and helps prevent slipping - even for greasy, oily hands.



Locking Tools

One-Hand Fast Release™

Introducing the new IRWIN® VISE-GRIP® Fast Release™ Locking Tool. It offers the strength and durability of The Original™ with the performance advantage of a release that is 2x easier to open. It unlocks from any angle without needing to press a trigger, making it ideal for professionals who work in tight spaces. The Fast Release locking tool also offers more finger room to accommodate large hands and professionals who wear gloves.



Adjusting Screw

- Provides exacting pressure
- Maintains pressure for repetitive use

2x Easier to Open

- No-pinch release
- More finger room

Handcrafted in the U.S.A

- High grade alloy steel
- Heat treated for maximum strength & life
- Cycle-tested durability: Locked 3000 times at a pressure of 2500 lbs.

Hardened Teeth

- Designed to grip from any angle
- Broached for maximum durability

Fast Release™ Models Available



Long Nose Locking Pliers



Curved Jaw Locking Pliers



Locking C-Clamps

800.866.5740

IRWIN. VISE-GRIP®

Curved Jaw Locking Pliers

- Curved jaws put tremendous pressure on four points of any style nut or bolt head

Model	Jaw Capacity	Size	<i>The Original</i> SINCE 1924™	<i>ProTouch</i> GRIPS	<i>One-Hand</i> <i>Fast Release</i> ™
10WR®	1-7/8" (48 mm)	10" (250 mm)	0502L3	05SG	05T
7WR®	1-1/2" (38 mm)	7" (175 mm)	0702L3	07SG	07T
5WR®	1-1/8" (29 mm)	5" (125 mm)	0902L3	09SG	09T
4WR®	15/16" (24 mm)	4" (100 mm)	1002L3		
10CR®	1-7/8" (48 mm)	10" (250 mm)	1102L3	11SG	
7CR®	1-1/2" (38 mm)	7" (175 mm)	1302L3	13SG	


* WR models include wire cutter feature



Straight Jaw Locking Pliers

- Straight jaws provide maximum contact on flat, square, or hex work

Model	Jaw Capacity	Size	<i>The Original</i> SINCE 1924™	<i>ProTouch</i> GRIPS	<i>One-Hand</i> <i>Fast Release</i> ™
10R®	1-3/4" (44 mm)	10" (250 mm)	0102L3	01SG	
7R®	1-5/16" (33 mm)	7" (175 mm)	0302L3	03SG	

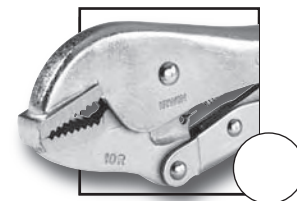

Long Nose Locking Pliers

- Long, straight nose provides easy access in narrow, hard-to-reach areas

Model	Jaw Capacity	Size	<i>The Original</i> SINCE 1924™	<i>ProTouch</i> GRIPS	<i>One-Hand</i> <i>Fast Release</i> ™
9LN®	2-3/4" (70 mm)	9" (225 mm)	1502L3	15SG	
6LN®	2" (51 mm)	6" (150 mm)	1402L3	14SG	14T
4LN®	1-1/2" (38 mm)	4" (100 mm)	1602L3		

* LN models include wire cutter feature



Bent Nose Locking Pliers

- Bent jaws provide off-angle access to tight spaces and allow for a better line of sight

Model	Jaw Capacity	Size	<i>The Original</i> SINCE 1924™	<i>ProTouch</i> GRIPS	<i>One-Hand</i> <i>Fast Release</i> ™
6BN®	2" (51 mm)	6" (150 mm)	144		

* BN model includes wire cutter feature



Locking Tools

Large Jaw Locking Pliers

- Heavy-duty jaws grip work of all shapes; ideal for plumbers, mechanics, & others working with large objects

Model	Jaw Capacity	Size	<i>The Original</i> SINCE 1924™	ProTouch GRIPS	<i>One-Hand</i> Fast Release™
12LC ®	3-1/8" (79 mm)	12" (300 mm)	12L3	12SG	
6LC ®	2" (51 mm)	6" (150 mm)	26	26SG	

* LC models include wire cutter feature



Locking C-Clamps with Regular Tips

- Wide-opening jaws provide greater versatility in clamping a variety of shapes


Model	Jaw Capacity	Size	<i>The Original</i> SINCE 1924™	ProTouch GRIPS	<i>One-Hand</i> Fast Release™
24R ™	10" (254 mm)	24" (605 mm)	275		
18DR ™	7-1/2" (190 mm)	18" (455 mm)	211		
18R ®	8" (200 mm)	18" (455 mm)	21		
11R ®	3-3/8" (85 mm)	11" (275 mm)	19		19T
9DR ™	4-1/2" (112 mm)	9" (225 mm)	30		
6R ®	2-1/8" (54 mm)	6" (150 mm)	17		17T



Locking C-Clamps with Swivel Pads

- Swivel pads hold tapered work, awkward fabricating jobs and delicate projects without damaging the work surface

Model	Jaw Capacity	Size	<i>The Original</i> SINCE 1924™	ProTouch GRIPS	<i>One-Hand</i> Fast Release™
24SP ™	10" (254 mm)	24" (605 mm)	28		
18SP ™	8" (200 mm)	18" (455 mm)	22		
11SP ®	3-3/8" (85 mm)	11" (275 mm)	20		
9SP ™	4-1/2" (112 mm)	9" (225 mm)	31		
6SP ™	2-1/8" (54 mm)	6" (150 mm)	18		
4SP ™	1-5/8" (41 mm)	4" (100 mm)	165		

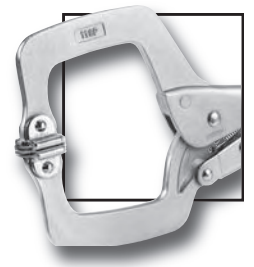

Locking Wrenches

- Heavy duty jaws lock onto three sides of a hex fastener and will not slip or mar

Model	Jaw Capacity	Size	<i>The Original</i> SINCE 1924™	ProTouch GRIPS	<i>One-Hand</i> Fast Release™
10LW ®	1-1/8" (29 mm)	10" (250 mm)	02	02SG	
7LW ®	3/4" (19 mm)	7" (175 mm)	04	04SG	
4LW ®	9/16" (14 mm)	4" (100 mm)	08		

* LW models include wire cutter feature



800.866.5740

Specialty Locking Tools

Locking Sheet Metal Tool

- Makes bending, forming and crimping sheet metal jobs easier

Model	Jaw Capacity	Throat Depth	Jaw Depth	Size	<i>The Original</i> SINCE 1924™
8R®	3-1/8" (78 mm)	1-3/4" (44 mm)	3-1/8" (78 mm)	8" (200 mm)	23



Locking Welding Clamp

- For use in welding applications or holding awkward shapes in place


Model	Jaw Capacity	Throat Depth	Jaw Depth	Size	<i>The Original</i> SINCE 1924™
9R®	2-3/4" (70 mm)	1-5/8" (41 mm)	2-3/4" (70 mm)	9" (225 mm)	25



Locking Panel Clamp

- Provides quick clamping and alignment of auto body and other sheet metal panels


Model	Jaw Capacity	Throat Depth	Jaw Depth	Size	<i>The Original</i> SINCE 1924™
9AC®	3/8" (10 mm)	7/32" (6 mm)		9" (225 mm)	251

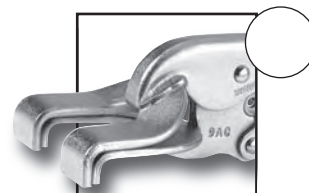

Locking Chain Clamp

- Chain holds and locks around any shape or size

Model	Jaw Capacity	Throat Depth	Jaw Depth	Size	<i>The Original</i> SINCE 1924™
20R®	18" (455 mm)			9" (225 mm)	27

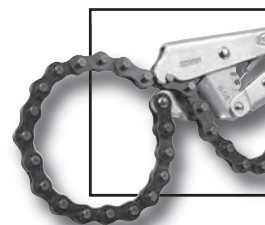

Locking Pinch Off Tool

- Pinches off and locks onto tubing, leaving both hands free to do other work

Model	Jaw Capacity	Throat Depth	Jaw Depth	Size	<i>The Original</i> SINCE 1924™
RR®	1/4" (6 mm)	1" (25 mm)		7" (175 mm)	29



Sets

Clamshell Sets

* Additional Clamshell Sets Available



**One-Hand
Fast Release™**

Fast Release® Locking Pliers 2 pc. Set
10WR®, 6LN®
#77T



**One-Hand
Fast Release™**

Fast Release® Locking Pliers 2 pc. Set
10WR®, 7WR®
#214T



The Original® Locking Pliers 3 pc. Set
10R®, 6LN®, 5WR®
#611



ProTouch® Locking Pliers 2 pc. Set
10WR®, 5WR®
#82SG

Kitbag Sets

* Additional Kitbag Sets Available



The Original® Locking Tools 10 pc. Set with Kitbag
10R®, 10WR®, 7R®, 7WR®, 7LW®, 5WR®, 6LN®, 9LN®, 6R®, 11R®
#1078KB



ProTouch® Locking Tools 7 pc. Set with Kitbag
10LW®, 10WR®, 7WR®, 7LW®, 5WR®, 6LN®, 12LC®
#757KBSG



ProTouch® Locking Pliers 5 pc. Set with Kitbag
10R®, 10CR®, 7WR®, 6LN®, 5WR®
#538KBSG

Specialty Sets

* Additional Specialty Sets Available



The Original® Locking Clamps 5 pc. Set with T-Shirt
10R®, (2) 11R®, (2) 6R®
#74



ProTouch® Locking Tools 10 pc. Set in Tray
10R®, 10WR®, 7R®, 7WR®, 7LW®, 5WR®, 6LN®, 9LN®, 6R®, 11R®
#1078TRSG



The Original® Locking Tools 25 pc. Counter Display
4WR®
#10CD

800.866.5740

IRWIN® VISE-GRIP®

ITEM #	DESCRIPTION	Tool Model	UPC#	PACK QTY.
FAST RELEASE™ LOCKING PLIERS				
05T	10" Curved Jaw with Wire Cutter	10WR®	0 38548 06748 3	5
07T	7" Curved Jaw with Wire Cutter	7WR®	0 38548 06749 0	5
09T	5" Curved Jaw with Wire Cutter	5WR®	0 38548 06750 6	5
14T	6" Long Nose	6LN®	0 38548 06751 3	5
19T	11" C-Clamp	11R®	0 38548 06752 0	5
17T	6" C-Clamp	6R®	0 38548 06753 7	5

THE ORIGINAL™ LOCKING & SPECIALTY TOOLS

0502L3	10" Curved Jaw with Wire Cutter	10WR®	0 38548 00504 1	5
0702L3	7" Curved Jaw with Wire Cutter	7WR®	0 38548 00704 5	5
0902L3	5" Curved Jaw with Wire Cutter	5WR®	0 38548 00904 9	5
1002L3	4" Curved Jaw with Wire Cutter	4WR®	0 38548 01004 5	5
0102L3	10" Straight Jaw	10R®	0 38548 00104 3	5
0302L3	7" Straight Jaw	7R®	0 38548 00304 7	5
1502L3	9" Long Nose	9LN®	0 38548 01504 0	5
1402L3	6" Long Nose	6LN®	0 38548 01404 3	5
1602L3	4" Long Nose	4LN®	0 38548 01604 7	5
12L3	12" Large Capacity	12LC®	0 38548 01201 8	5
26	6" Large Capacity	6LC®	0 38548 00126 5	5
19	11" C-Clamp	11R®	0 38548 00019 0	5
30	9" C-Clamp	9DR™	0 38548 00300 9	5
17	6" C-Clamp	6R®	0 38548 00017 6	5
20	11" C-Clamp with Swivel Pads	11SP®	0 38548 00020 6	5
31	9" C-Clamp with Swivel Pads	9SP™	0 38548 00310 8	5
18	6" C-Clamp with Swivel Pads	6SP™	0 38548 00018 3	5
23	8" Sheet Metal Tool	8R®	0 38548 00023 7	1
25	9" Welding Clamp	9R®	0 38548 00025 1	1

* Additional Products Available

PROTOUCH™ LOCKING TOOLS

05SG	10" Curved Jaw with Wire Cutter	10WR®	0 38548 03005 0	5
07SG	7" Curved Jaw with Wire Cutter	7WR®	0 38548 03007 4	5
09SG	5" Curved Jaw with Wire Cutter	5WR®	0 38548 03009 8	5
01SG	10" Straight Jaw	10R®	0 38548 03001 2	5
03SG	7" Straight Jaw	7R®	0 38548 03003 6	5
15SG	9" Long Nose	9LN®	0 38548 03015 9	5
14SG	6" Long Nose	6LN®	0 38548 03014 2	5
12SG	12" Large Capacity	12LC®	0 38548 03012 8	5
26SG	6" Large Capacity	6LC®	0 38548 03026 5	5

* Additional Products Available

SETS

214T	Fast Release™ Locking Pliers 2 pc. Set	10WR®, 7WR®	0 38548 06754 4	5
77T	Fast Release™ Locking Pliers 2 pc. Set	10WR®, 6LN®	0 38548 06755 1	5
37	The Original™ Locking Pliers 2 pc. Set	10WR®, 5WR®	0 38548 00037 4	5
641	The Original™ Locking Pliers 6 pc. Set with Kitbag & Koozies	10WR®, 9LN®, 7WR®, 6LN®, 5WR®, 4LN®	0 38548 00641 3	1
68	The Original™ Locking Pliers 5 pc. Set with Kitbag	10R®, 10CR®, 7WR®, 6LN®, 5WR®	0 38548 00068 8	1
71	The Original™ Locking Pliers 4 pc. Set with Kitbag	10CR®, 7R®, 6LN®, 5WR®	0 38548 00071 8	1
73	The Original™ Locking Pliers 3 pc. Set with Kitbag	10WR®, 6LN®, 5WR®	0 38548 00073 2	1
74	The Original™ Locking Clamps 5 pc. Set with T-Shirt	10R®, (2) 11R®, (2) 6R®	0 38548 00074 9	1
1078TRAY	The Original™ Locking Tools 10 pc. Set with Tray	10R®, 10WR®, 7R®, 7WR®, 7LW®, 5WR®, 6LN®, 9LN®, 6R®, 11R®	0 38548 01878 2	1
1078KB	The Original™ Locking Tools 10 pc. Set with Kitbag	10R®, 10WR®, 7R®, 7WR®, 7LW®, 5WR®, 6LN®, 9LN®, 6R®, 11R®	0 38548 01078 6	1
538KBSG	ProTouch™ Locking Tools 5 pc. Set with Kitbag	10R®, 10CR®, 7WR®, 6LN®, 5WR®	0 38548 03538 3	1
757KBSG	ProTouch™ Locking Tools 7 pc. Set with Kitbag	10WR®, 7WR®, 6LN®, 10LW®, 7LW®, 5WR®, 12LC®	0 38548 03757 8	1
1078TRSG	ProTouch™ Locking Tools 10 pc. Set with Tray	10R®, 10WR®, 7R®, 7WR®, 7LW®, 5WR®, 6LN®, 9LN®, 6R®, 11R®	0 38548 01778 5	1
82SG	ProTouch™ Locking Tools 2 pc. Set	10WR®, 5WR®	0 38548 03082 1	5

* Additional Products Available

Dealer:

NO INK NO VARNISH

©2005

IRWIN®

Industrial Tools
Huntersville, NC 28078
1-800-866-5740



G05528

VG05-200

www.irwin.com