


# Scotch™ Washi Tapes 2899 and 244

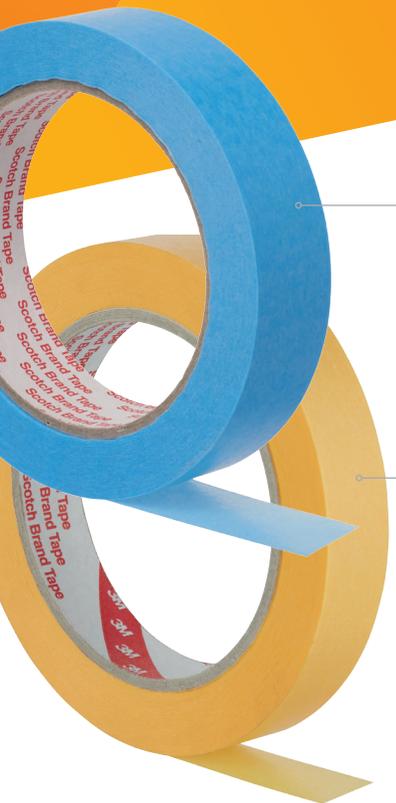

**Residue-free removal, for indoor and outdoor paint masking applications. High temperature and UV resistant.**

Masking tapes	2899	244
Clean removal	60 days	180 days
Sharp paintline	✓✓✓	✓✓✓✓
Thickness	0.08mm	0.085mm
Tensile strength at break	29N/10mm	30.4N/10mm
Temperature performance	150°C (1 hour)	100°C (30 mins)
Backing resists bleed through	●●●●	●●●●●

3M™ Scotch™ Washi Tape 2899

3M™ Scotch™ Washi Tape 244

## 3M Industrial Adhesives and Tapes Division

3M United Kingdom plc  
3M Centre  
Cain Road, Bracknell  
Berkshire RG12 8HT  
0870 60 800 60  
www.3M.co.uk/industrial

3M Ireland Limited  
The Iveagh Building  
The Park  
Carrickmines  
Dublin 18  
1 800 320 500

Please recycle. Printed in the UK. 3M and Scotch are trademarks of the 3M company. Used under licence by 3M subsidiaries and affiliates. © 3M 2017. All rights reserved. J371373. CJ1243

