




ISOLATING TRANSFORMER

POWER : 2.3VA  
 INPUT VOLTAGE : 230V  
 FREQUENCY : 50/60Hz  
 NOMINAL OUTPUT VOLTAGE : 2x24V


INHERENTLY SHORT CIRCUIT PROOF TRANSFORMER  
 IPOO  
 UL94V0  
 OPERATING TEMPERATURE : -25°C to 70°C  
 STORAGE TEMPERATURE : -25°C to 85°C  
 INSULATION CLASS (IEC85) : B  
 INHERENT PROTECTION

STANDARDS :  
 UL506 (File E111078)  
 CSA 22-2 (File E111078)  
 CE

CONFORM TO :  
 EN61558-1  
 EN61558-2-4

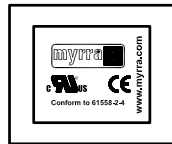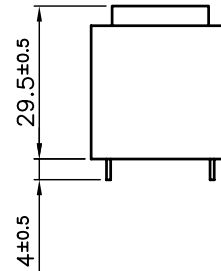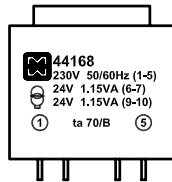

<b>44168</b> 230V 50/60Hz (1-5) 24V 1.15VA (6-7) 24V 1.15VA (9-10) ① ta 70/B ⑤	   Conform to 61558-2-4 <a href="http://www.myrra.com">www.myrra.com</a>	N°23
--	--	------

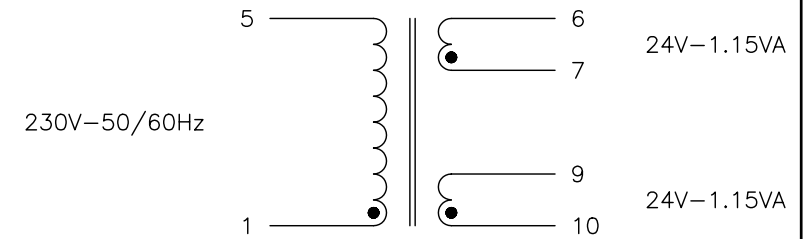

Finition:		Tolérance générale:	
Finition:		General tolerance:	
Ech: 1:1	Matière:		
	Material:		
Dessiné par: ROUSSEL.Ch	Date: 18/05/2004	Visa:	J.P.M.

D					
C					
B					
A					
Rev	Date	Modification	Dessiné	Visa	

<b>DATA SHEET 44168</b>	
<b>EI 30x18</b>	
	22 Allée du Clos des Charmes Z.A. Les Portes de la Forêt 77090 COLLEGIEN Tel : 01-60-37-55-55 Fax : 01-60-17-12-00
<b>DS44168</b>	