
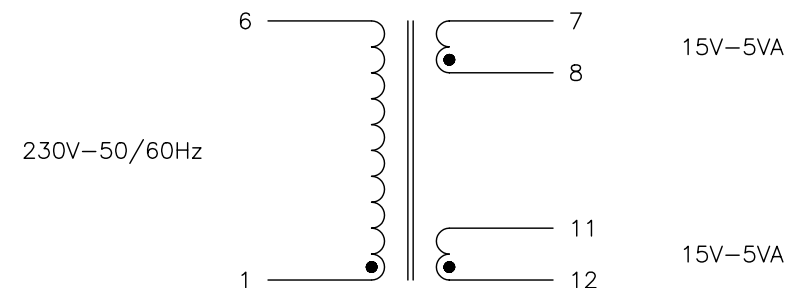
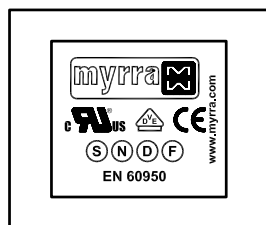
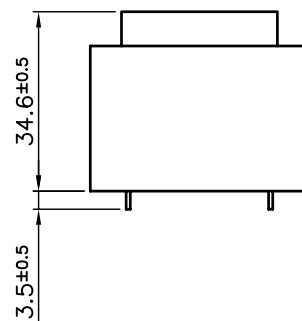


SAFETY ISOLATING TRANSFORMER

POWER : 10VA
 INPUT VOLTAGE : 230V
 FREQUENCY : 50/60Hz
 NOMINAL OUTPUT VOLTAGE : 2x15V

NON SHORT CIRCUIT PROOF TRANSFORMER
 IP00
 UL94V0
 OPERATING TEMPERATURE : -25°C to 50°C
 STORAGE TEMPERATURE : -25°C to 85°C
 INSULATION CLASS (IEC85) : B
 REQUIRED PROTECTION : 63mA FUSE ON PRIMARY

STANDARDS :
 UL506 (File E111078)
 CSA 22-2 (File E111078)
 VDE (File Ref:1398300)
 EN60950 (File Ref:1398300)
 EN61558-1 (File Ref:1398300)
 EN61558-2-6 (File Ref:1398300)
 CE

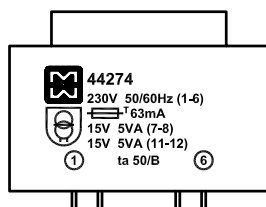

Finition:		Tolérance générale:	
Finition:		General tolerance:	
Ech: 1:1	Matière:		
	Material:		
Dessiné par: ROUSSEL.Ch	Date: 09/02/2003	Visa:	J.P.M.

D					
C					
B					
A					
Rev	Date	Modification	Dessiné	Visa	

DATA SHEET 44274
EI 48x16.8

22 Allée du Clos des Charmes
 Z.A. Les Portes de la Forêt
 77090 COLLEGIEN
 Tel : 01-60-37-55-55
 Fax : 01-60-17-12-00

DS44274