


Parts Information: Transmission Jack 0.8tonne Vertical Telescopic Model No: 800TTJ

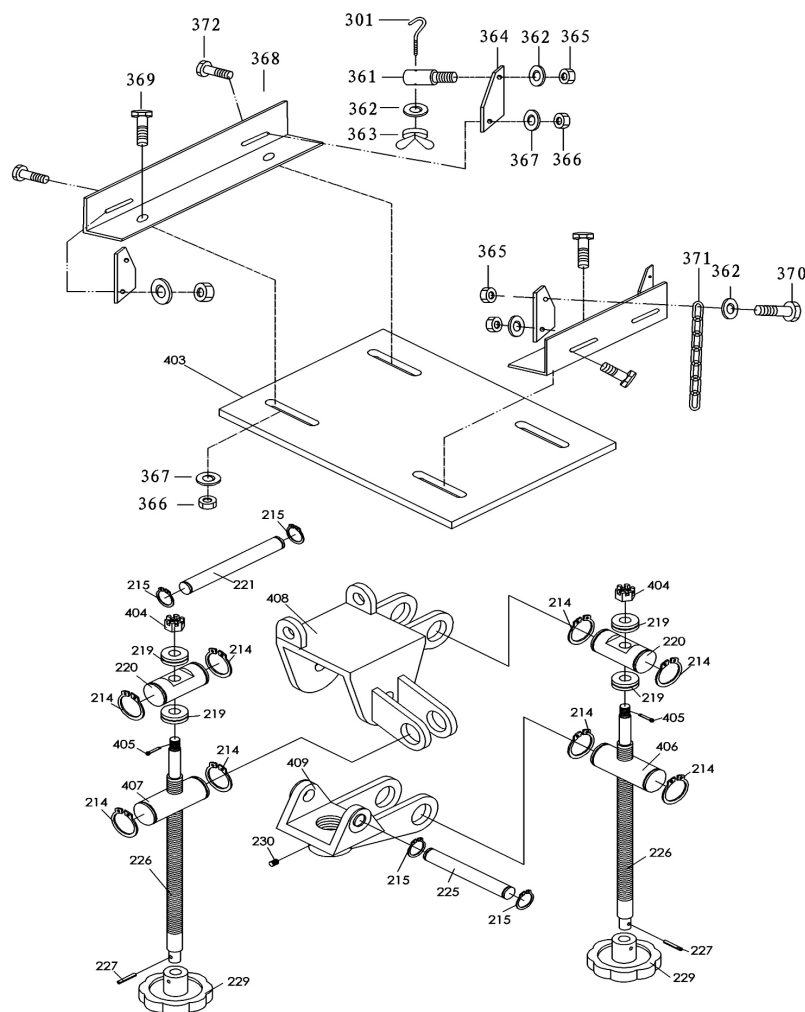

Item	Part No.	Description
214	800TTJ.214	RETAINING RING
215	800TTJ.215	RETAINING RING
219	B/51101	BEARING RACE 51101
220	800TTJ.220	ADJUSTMENT PIN
221	800TTJ.221	PIN
225	800TTJ.225	PIN
226	800TTJ.226	TILT SCREW
227	800TTJ.227	ROLL PIN
229	800TTJ.229	TILT SCREW GRIP
230	800TTJ.230	GRUB SCREW
301	800TTJ.301	HOOK BOLT
361	800TTJ.361	HOOK BOLT PIN
362	800TTJ.362	WASHER
363	SN8.SW	WING NUT M8 (SINGLE)
364	800TTJ.364	SIDE ANGLE

Item	Part No.	Description
365	SN8.S	STEEL NUT M8 ZINC DIN934 (SINGLE)
366	800TTJ.366	NUT
367	800TTJ.367	WASHER
368	800TTJ.368	SIDE PLATE
369	SS1025.S	HEX HEAD SET SCREW M10x25mm SINGLE
370	SS825.S	HEX HEAD SET SCREW M8x25mm SINGLE
371	800TTJ.371	CHAIN
372	SS1025.S	HEX HEAD SET SCREW M10x25mm SINGLE
403	800TTJ.403	SADDLE PLATE
404	800TTJ.404	CASTLE NUT
405	800TTJ.405	SPLIT PIN
406	800TTJ.406	ADJUSTMENT PIN
407	800TTJ.407	ADJUSTMENT PIN
408	800TTJ.408	SADDLE BASE, UPPER
409	800TTJ.409	SADDLE BASE, LOWER

NOTE: It is our policy to continually improve products and as such we reserve the right to alter data, specifications and component parts without prior notice.

IMPORTANT: No liability is accepted for incorrect use of product.

WARRANTY: Guarantee is 12 months from purchase date, proof of which will be required for any claim.

Sealey Group, Kempson Way, Suffolk Business Park, Bury St Edmunds, Suffolk. IP32 7AR



01284 757500




01284 703534



sales@sealey.co.uk



www.sealey.co.uk

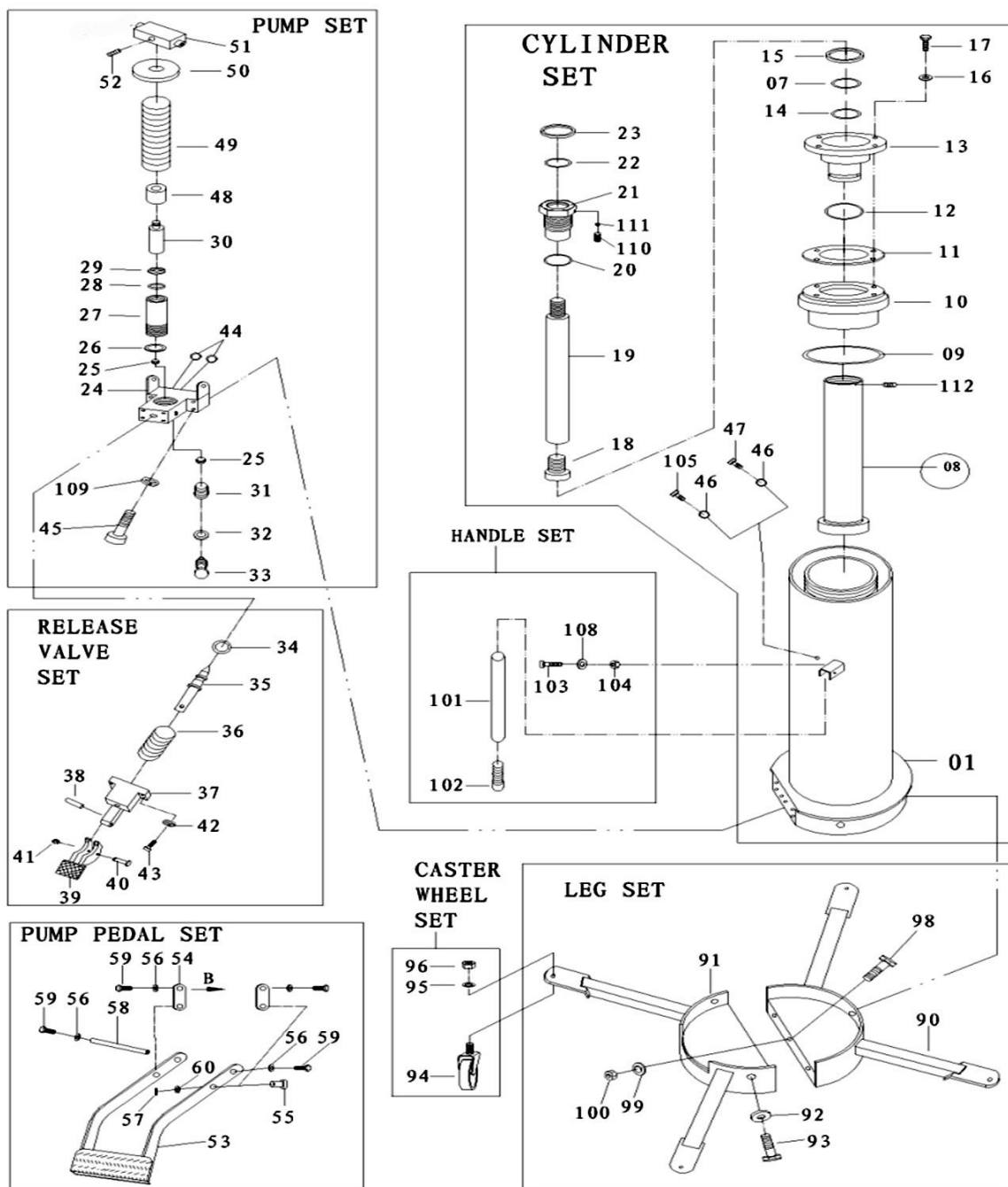

NOTE: It is our policy to continually improve products and as such we reserve the right to alter data, specifications and component parts without prior notice.

IMPORTANT: No liability is accepted for incorrect use of product.

WARRANTY: Guarantee is 12 months from purchase date, proof of which will be required for any claim.



Parts Information:
**Transmission Jack 0.8tonne Vertical
Telescopic
Model No: 800TTJ**

1	800TTJ.01	CYLINDER ASS'Y
7	800TTJ.07	O-RING (65x5.7)
8	800TTJ.08	RAM
9	800TTJ.09	O-RING (140x5.7)
10	800TTJ.10	TOP NUT
11	800TTJ.11	GASKET SEAL
12	800TTJ.12	O-RING 65x3.1
13	800TTJ.13	FLANGE
14	800TTJ.14	O-RING 60x3.1
15	800TTJ.15	DUST SEAL
16	FWM10.S	FLAT WASHER M10 SINGLE
17	800TTJ.17	BOLT M10x30
18	800TTJ.18	RETAINER RAM
19	800TTJ.19	RAM
20	800TTJ.20	O-RING 48x3.5
21	800TTJ.21	TOP NUT
22	800TTJ.22	O-RING 41x3.5
23	800TTJ.23	DUST SEAL
24	800TTJ.24	PUMP BASE ASS'Y
25	SB-8.0	STEEL BALL 8.0mm
26	500TTJ.P26	WASHER COPPER M26 THIN
27	800TTJ.27	PUMP CYLINDER
28	800TTJ.28	O-RING 30x3.1
29	800TTJ.29	DUST SEAL
30	800TTJ.30	PUMP PISTON
31	800TTJ.31	SPRING
32	800TTJ.32	SEAL WASHER
33	800TTJ.33	SCREW
34	1000ETJ.31	O-RING 12X1.9
35	800TTJ.35	RELEASE VALVE ROD
36	800TTJ.36	SPRING
37	800TTJ.37	BASE RELEASE VALVE
38	800TTJ.38	PIN 6x32
39	800TTJ.39	PEDAL RELEASE VALVE
40	800TTJ.40	PIN
41	800TTJ.41	COTTER PIN
42	SWM6.S	SPRING WASHER M6 ZINC (SINGLE)
43	800TTJ.43	SCREW M6x25
44	500TTJ.P44	O-RING (11x1.9mm)

Item	Part No.	Description
45	800TTJ.45	SCREW M10x55
46	800TTJ.46	O-RING 14x2.4
47	800TTJ.47	AIR VENT VALVE
48	800TTJ.48	DUST CAP
49	800TTJ.49	SPRING
50	800TTJ.50	SPRING RETAINER
51	800TTJ.51	CONNECT ROD
52	800TTJ.52	SCREW M8x10
53	800TTJ.53	PEDAL
54	800TTJ.54	LINK
55	800TTJ.55	COTTER LINK 14x20
56	RW825.S	REPAIR WASHER M8x25 (SINGLE)
57	800TTJ.57	PIN 4x20
58	800TTJ.58	CONNECTING ROD
59	800TTJ.59	BOLT M8x12
60	FWM12.S	FLAT WASHER M12 SINGLE
90	800TTJ.90	LEG ASS'Y
91	800TTJ.91	LEG ASS'Y
92	FWM12.S	FLAT WASHER M12 SINGLE
93	800TTJ.93	BOLT M12x30
94	800TTJ.94	WHEEL,CASTOR (88x10x30x114)
95	SWM12.S	SPRING WASHER M12 ZINC (SINGLE)
96	SN12.S	STEEL NUT M12 ZINC DIN934(SINGLE)
98	800TTJ.98	BOLT M10x25
99	SWM10.SB	SPRING WASHER M10 BLACK(SINGLE)
100	SN10.S	STEEL NUT M10 ZINC DIN934(SINGLE)
101	800TTJ.101	HANDLE
102	800TTJ.102	HANDLE GRIP
103	800TTJ.103	BOLT (M10x45)
104	SN10.S	STEEL NUT M10 ZINC DIN934(SINGLE)
105	800TTJ.105	FILLER PLUG
108	FWM10.S	FLAT WASHER M10 SINGLE
109	SWM10.SB	SPRING WASHER M10 BLACK(SINGLE)
110	GSM56.S	GRUB SCREW M5x6 (SINGLE)
111	SB-4.7	STEEL BALL 4.7mm
112	GSM56.S	GRUB SCREW M5x6 (SINGLE)

NOTE: It is our policy to continually improve products and as such we reserve the right to alter data, specifications and component parts without prior notice.

IMPORTANT: No liability is accepted for incorrect use of product.

WARRANTY: Guarantee is 12 months from purchase date, proof of which will be required for any claim.

Sealey Group, Kempson Way, Suffolk Business Park, Bury St Edmunds, Suffolk. IP32 7AR



01284 757500



01284 703534



sales@sealey.co.uk



www.sealey.co.uk