




**SPECIFICATION  
CONTROL DRAWING  
Crystal Resonator**

**FREQUENCY**

32.768000kHz

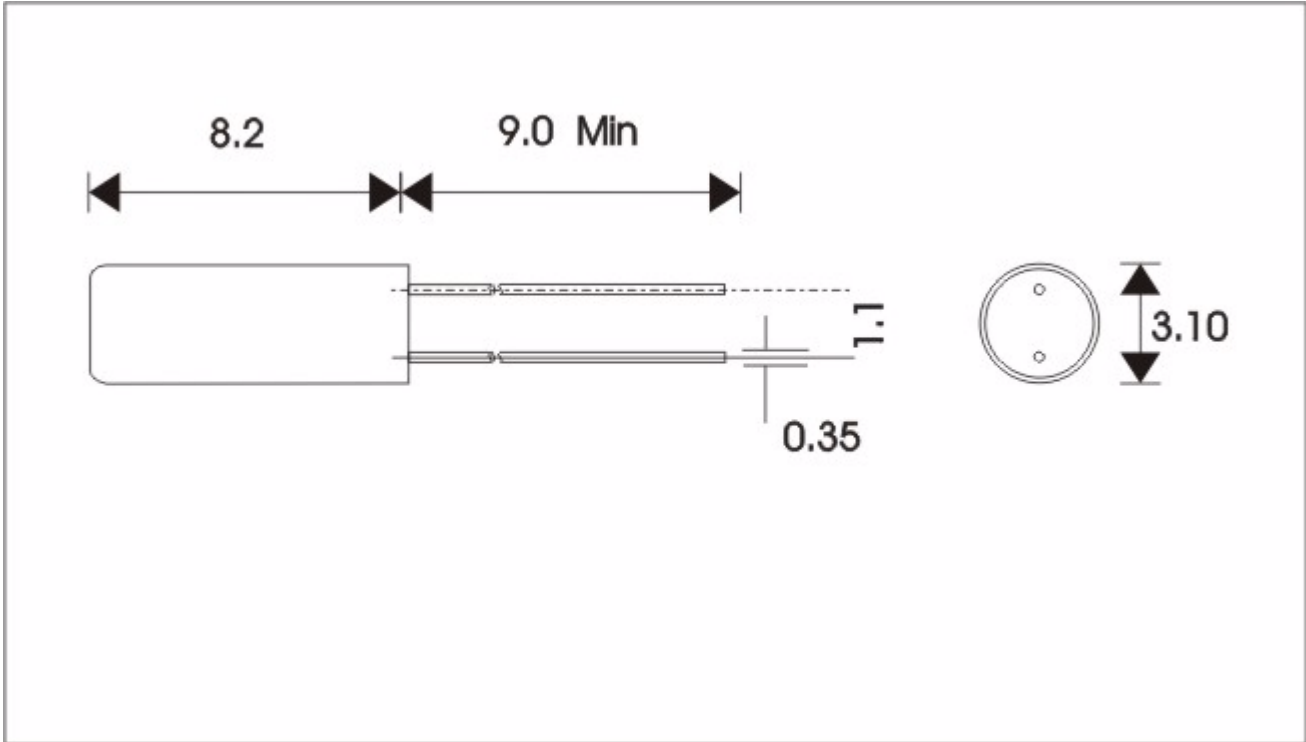

Holder Style	3x8 Cyl
Mode	Fundamental
Adjustment Tolerance	± 20PPM at 25°C
Operating Temp. Range	-10°C to +60°C
Load Capacitance	6 pF
ESR	35K Ohm
Static Capacitance (C0)	0.9 pF
Dynamic Capacitance (C1)	2.1 fF
Ageing	+/-3PPM 1st Year
Marking	AEL32.768

Amdt Date	Change Note	AEL Code
		<b>X32K768L017</b>
		<b>Issue Ref</b> A