




**SPECIFICATION
CONTROL DRAWING
Crystal Resonator**

FREQUENCY
32.768000kHz

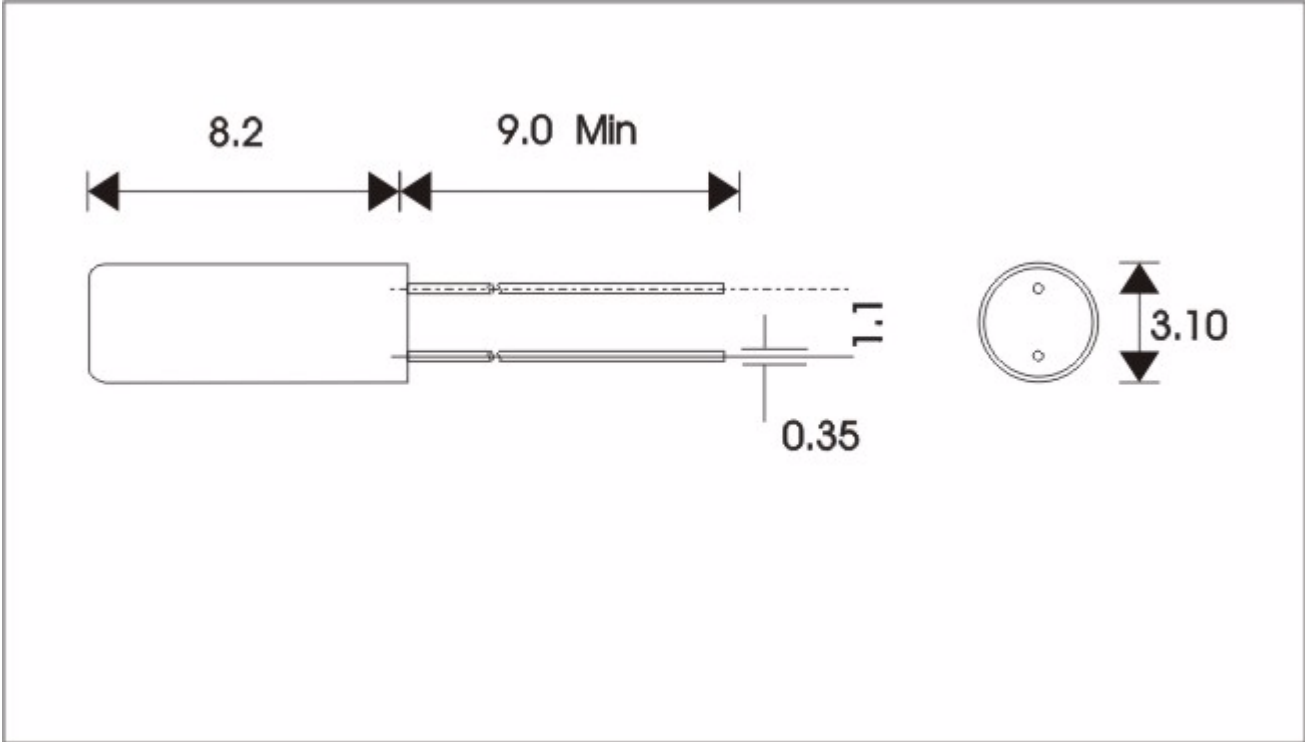

Holder Style	3x8 Cyl
Mode	Fundamental
Adjustment Tolerance	± 20PPM at 25°C
Operating Temp. Range	-10°C to +60°C
Load Capacitance	12.5 pF
ESR	50K Ohm
Static Capacitance (C0)	1.3 typ pF
Dynamic Capacitance (C1)	0.0024 typ fF
Ageing	+/-5PPM 1st Year
Marking	AEL32.768

Amdt Date	Change Note	AEL Code
		X32K768L101
		Issue Ref A